




Dimensions (In.)

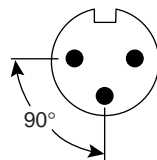

164-2321
180° of arc
3 way

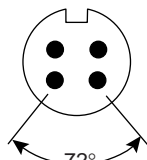

164-2421
216° of arc
4 way

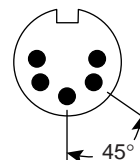

164-2521
180° of arc
5 way

Specifications:

- Working voltage: 100VDC or VAC peak
- Test voltage: 1000VDC
- Current rating: 4A
- Insulation resistance: 10⁹Ω min. @ 100VDC
- Contact resistance: 10mΩ max.
- Capacity (mated): 3pF
- Temperature range: -25°C to +70°C
- Pin base moldings: nylon
- Contacts: silver plated brass
- Cable clamps: plated mild steel
- Grommets: black PVC
- Housing: zinc alloy finished with matt black plating over copper