




Heyco® Open/Closed Bushings

PANEL DIMENSIONS				PART NO.		DESCRIPTION	PART DIMENSIONS					
Maximum Thickness		Mounting Hole Diameter		Black	White		A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.
.125	3,2	.375	9,5	2865	2885	OCB-375	.265	6,7	.421	10,7	.390	9,9
.125	3,2	.437	11,1	2867	2887	OCB-437	.312	7,9	.500	12,7	.406	10,3
.125	3,2	.500	12,7	2871	2891	OCB-500	.312	7,9	.562	14,3	.406	10,3
.125	3,2	.562	14,3	2869	2889	OCB-562	.390	9,9	.640	16,3	.406	10,3
.125	3,2	.625	15,9	2872	2892	OCB-625	.453	11,5	.687	17,5	.406	10,3
.125	3,2	.750	19,0	2873	2893	OCB-750	.546	13,9	.796	20,2	.406	10,3
.125	3,2	.875	22,2	2874	2894	OCB-875	.671	17,7	.921	23,4	.406	10,3
.125	3,2	1.000	25,4	2878	2898	OCB-1000	.812	20,6	1.047	26,6	.406	10,3
.125	3,2	1.093	27,8	2879	2899	OCB-1093	.875	22,2	1.156	29,4	.406	10,3
.125	3,2	1.250	31,8	2881	2884	OCB-1250	1.046	26,6	1.343	34,1	.406	10,3
.125	3,2	1.375	34,9	2882	2886	OCB-1375	1.171	29,7	1.468	37,3	.406	10,3
.125	3,2	1.500	38,1	2883	2888	OCB-1500	1.250	31,7	1.578	40,1	.421	10,7

Standard Colors: Black or White. Consult factory for color matching, prices, and minimum order quantities. Locking fingers in fractional increments up to the maximum panel thickness.

- Twelve sizes for use in mounting holes from 3/8" (9,5mm) to 1-1/2" (38,1mm).
- Split design allows side entry and encirclement of preassembled harnesses, capillary tubes or other assemblies that have segments larger than the bushing's ID.
- May also be assembled into holes that already contain cable, wire or other filaments.
- Fingertip pressure snap-locks the bushing into its mounting hole.

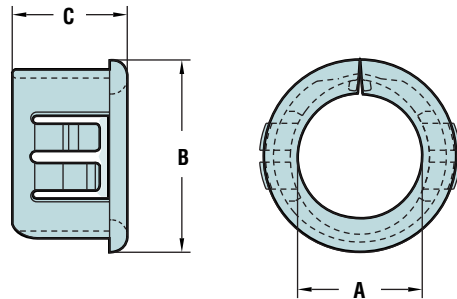

Material 6/6 "Nylon"
Certifications Recognized under the Component Program of Underwriters' Laboratories File #E-15331
 Certified by the Canadian Standards Association File #LR-8919
Flammability Rating 94V-2
Material Temperature Index 125°C—Maximum temperature on part not to exceed 105°C

Quick Specs