

MODEL TL-2155



International size reference: 2/3AA, ER14335

TECHNICAL DATA

(Typical values @+25°C for batteries stored for one year or less)



| | |
|--|------------------|
| ■ Nominal capacity @ 0.5 mA, to 2V | 1.45 Ah |
| ■ Rated voltage | 3.6 V |
| ■ Maximum recommended continuous current | 75 mA |
| ■ Maximum pulse current capability | 150 mA |
| ■ Weight | 12.4g (0.437 oz) |
| ■ Volume | 5.7 cc |
| ■ Operating temperature range | -55°C to +85°C |
| ■ U.L. Component Recognition, MH 12193 | |

TADIRAN LITHIUM BATTERIES

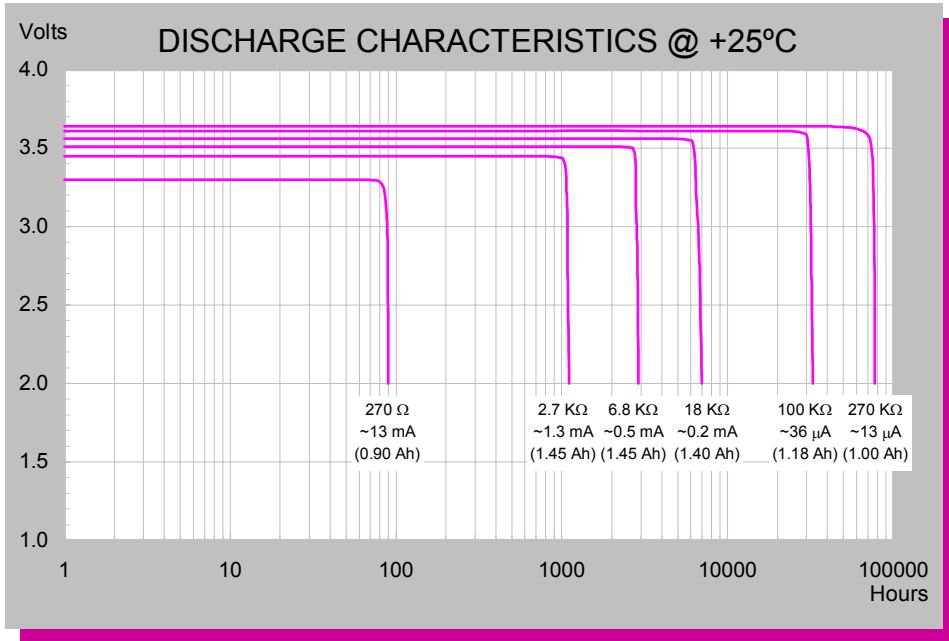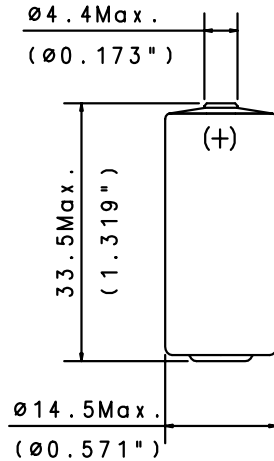

AVAILABLE TERMINATIONS

| | |
|----------------------------|---------------|
| SUFFIX- /S STANDARD | 15-5155-21500 |
| SUFFIX- /T SOLDER TABS | 15-5155-31500 |
| SUFFIX- /P AXIAL PINS | 15-5155-41500 |
| SUFFIX- /PT2 RADIAL PINS | 15-5155-36500 |
| SUFFIX- /TP POLARIZED TABS | 15-5155-52500 |
| SUFFIX- /PT POLARIZED TABS | 15-5155-53500 |

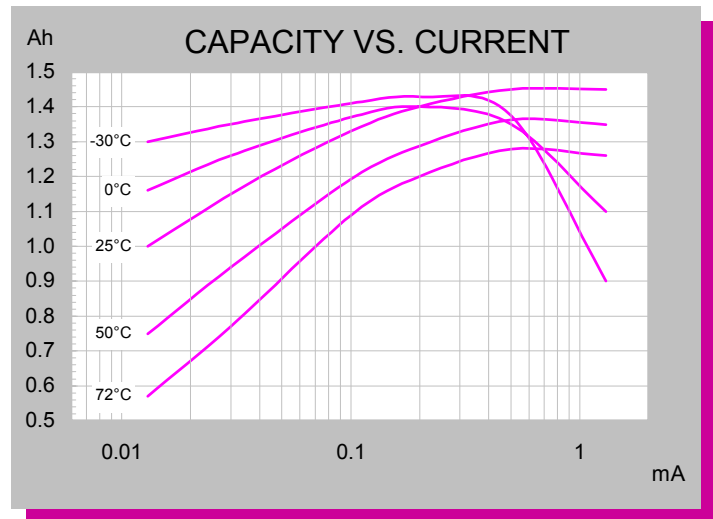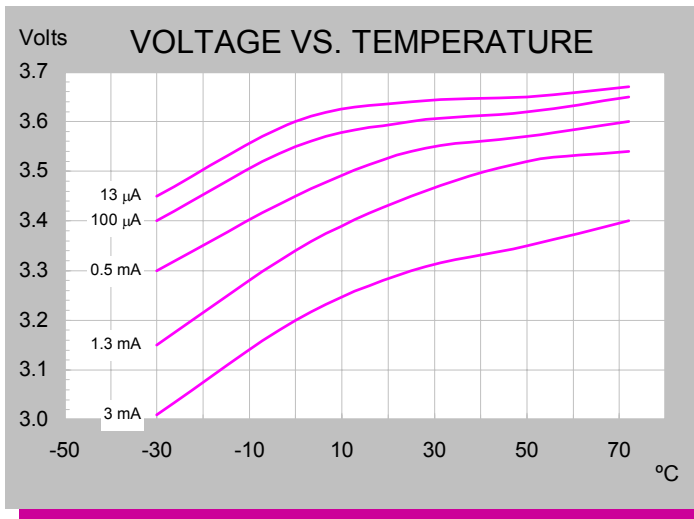

LITHIUM XTRA

Note: Any presentations in this data sheet concerning performance are for information purpose only and are not construed as warranties either expressed or implied, of future performance. Rev. B 04/03