


# Blackburn®

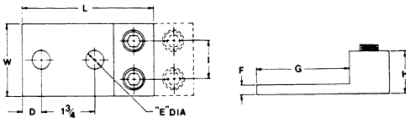

**T&B Catalog Number:** ADR35-22  
**UPC Number:** 78378661023  
**Description:** Type ADR-ALCUL Two-Conductor, Two-Hole Mount for Conductor Range Max 350 kcmil, Min 6 Str.  
**Status:** Active

### Features

Easy Installation - no special tools required.

### General

Style	ALCUL Two-Conductor, Two-Hole Mount
Material	Aluminum
Plating	Tin-Plated
Conductor Range (AL or CU) Maximum	350 kcmil
Conductor Range (AL or CU) Minimum	6 Str.

### Dimension Information

Length (inches)	4 1/4
Width (inches)	2 19/64
Height (inches)	1 3/8
D (inches)	5/8
E (inches)	1/2
F (inches)	5/16
G (inches)	3
I (inches)	1 7/32

### Packaging

T&B Inner Pack	3
Package in Units	30
T&B Sold in UOM	Each
T&B Weight Per UOM	37.17 lbs. per 100

### Notes

NEMA spacing 1 3/4 inch centers.  
 Connectors accomodating conductors 600 kcmil and larger have double rows of set screws (D suffix).  
 UL 486B tested, AL9CU rated

### Certifications

RoHS Compliance	Yes
-----------------	-----

### Certifications



File Nbr:  
E9809

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
 8155 T&B Blvd.  
 Memphis, TN 38125  
 www.tnb.com

T&B Technical Support  
 MS 3B-50  
 8155 T&B Blvd.  
 Memphis, TN 38125

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email:techsupport@tnb.com