



## Color-Keyed®

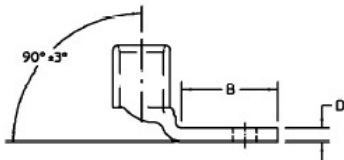

**T&B Catalog Number:** 54111UB  
**UPC Number:** 78621088693  
**Description:** Copper One-Hole Lug - 90 degree Standard Barrel - max 35KV, 3/0 AWG Wire, 3/8" Bolt Size, Tin Plated with Inspection Hole, Orange 50  
**Status:** Active

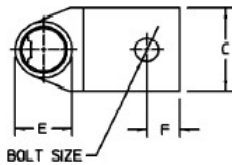

### General

-Material	Copper
-Finish	Tin Plated
-Wire Size	3/0 AWG
-Number of Studs	1
-Stud Size	3/8
-Tongue Angle	90
-Barrel Length	Standard
-Barrel Shape	Standard
-Tongue Width	Standard
-Peep Hole	Y
-Marking	Standard
-Hole Shape	Round
-Die Color	Orange
-Die Code	50

### Dimension Information

-A (inches)	1.531
-B (inches)	0.813
-C (inches)	0.938
-D (inches)	0.141
-E (inches)	0.625
-F (inches)	0.375

### Packaging

-T&B Order Multiple	10
-T&B Inner Pack	10
-Package in Units	100
-T&B Sold in UOM	Each
-T&B Weight Per UOM	8.1 lbs. per 100

### Application Support

-T&B Instruction Sheets	ta00675-tb2
-Overview	Available on Website
-Connector & Tooling Chart	Available on Website

### Notes

- Dimensions given for reference only. Dimensions may vary up to -

### Certifications

-RoHS Compliance	Yes
------------------	-----

### Certifications



File Nbr:  
E9809

For further technical assistance, please contact us...

8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)