



# Block Forks - Vinyl Insulated Butted Seam 22-18 AWG

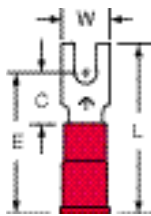


Product Number†	UPC (054007-)	Wire Range (AWG)	Stud Size	W	C	L	E	Thickness	Barrel Length	Barrel I.D.	Maximum Insulation Diameter	Terminals per Case
MVU18-4FB/SK	02253	22-18	4	0.25	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-6FB/SK	01218	22-18	6	0.25	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-6FBK	01219	22-18	6	0.30	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-8FBK	01220	22-18	8	0.30	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000
MVU18-10FBK	01221	22-18	10	0.30	0.25	0.85	0.70	0.030	0.25	0.070	0.145	1000




**MVU18-4FB/S**  
Stud Size 4  
Wire Range 22-18

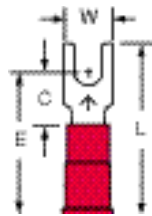


**MVU18-6FB/S**  
Stud Size 6  
Wire Range 22-18

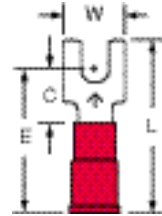

**MVU18-6FB**  
Stud Size 6  
Wire Range 22-18

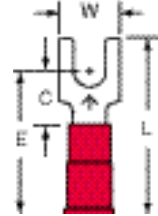

**MVU18-8FB**  
Stud Size 8  
Wire Range 22-18

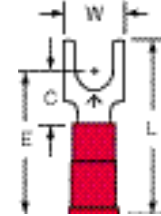

**MVU18-10FB**  
Stud Size 10  
Wire Range 22-18

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

3M:

[MVU18-10FBK](#)