



STEALTH Cutters




- Premium Wire Cutters
- High performance alloy steel
 - Non-reflective satin finish
 - 60-63 HRC
 - Precision screw joint construction




- Comfortable Grip
- ESD Safe Comfort Grips
 - Designed for all hand sizes
 - Dual Leaf Springs



- The Right Cutters For The Right Job
- Oval head, tapered head, and angled cutters
 - Available with flush or semi-flush cutting blades

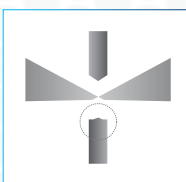

Flush Blade

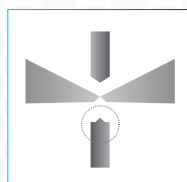

Semi-Flush Blade



Smooth Cutting Performance

Aven Stealth Cutters are manufactured from a high performance alloy steel for exceptional strength and durability. The cutters feature a non-reflective satin finish, a unique screw-joint for perfect alignment of the cutting blades whilst minimizing friction, induction hardened cutting edges (60-63HRC) that is produced using a proprietary grinding process to ensure edge angle accuracy and ESD safe ergonomically designed grips. Each cutter is individually inspected and checked for quality and performance.

- High performance alloy steel
- Ergonomic ESD safe comfort hand grips
- Ultra-responsive leaf springs for reduced hand fatigue
- Non-reflective satin finish
- 60-63 HRC
- Screw joint construction for precise blade alignment
- Exceptional cutting performance



Head Style	Image	Part#	Cutting Capacity	Line Drawing
Oval Head		Flush: 10921F Semi-Flush: 10921S	Flush: 0.15-1.20mm Semi-Flush: 0.20-1.20mm	
Tapered Head		Flush: 10925F Semi-Flush: 10925S	Flush: 0.15 - 1.00mm Semi-Flush: 0.20-1.10mm	
Mini Oval Head		Flush: 10927F	0.10 - 1.00mm	
Mini Tapered Head w/Relief		Flush: 10928F	0.10 - 1.00mm	
Angulated Cutter Mini		Flush: 10934F	0.10 - 0.65mm	
Angulated Cutter Large		Flush: 10935F	0.10 - 0.65mm	
Extra Large Oval Head		Flush: 10923	.10 - 2.0mm	Line Drawing Coming Soon



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aven:](#)

[10922F](#) [10921F](#) [10921S](#)