


NYLON-INSULATED (STRAIGHT) BUTT SPLICE CONNECTORS

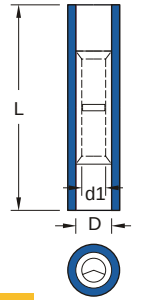

MAXIMUM ELECTRIC CURRENT:

A.W.G.	26	24	22	20	18	16	14	12	10	8	6	4	2
AMP.	5.5	7	9	12	17	18	30	35	50	70	95	125	170

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.

CONNECTOR MATERIAL: COPPER INSULATION MATERIAL: NYLON

INSULATION COLOR:

26-22 A.W.G.: YELLOW 22-16 A.W.G.: RED 16-14 A.W.G.: BLUE 12-10 A.W.G.: YELLOW
8 A.W.G.: RED 6 A.W.G.: BLUE 4 A.W.G.: YELLOW 2 A.W.G.: RED

WIRE RANGE A.W.G. mm ²	ITEM NO.	DIMENSION ^{inch} mm			MATERIAL	CRIMPING TOOL	Q'TY BOX
		L	D	d1			
26-22 A.W.G. 0.2-0.5 mm ²	BNYT0.5 ◇	.787 20.0	.079 2.0	.051 1.3	COPPER TUBULAR	K.S. MODEL LY8-067 HT-202A, HT-202B WITH DIE INDEX NO:0.5	1000
22-18 A.W.G. 0.5-1.5 mm ²	BNYT1	1.063 27.0	.126 3.2	.067 1.7	COPPER TUBULAR	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	BNYT1-16						
16-14 A.W.G. 1.5-2.5 mm ²	BNYT2	1.063 27.0	.150 3.8	.091 2.3	COPPER TUBULAR	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	BNYT2-16						
12-10 A.W.G. 4-6 mm ²	BNYT5	1.063 27.0	.209 5.3	.134 3.4	COPPER TUBULAR	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
	BNYT5-18						
	BNYT5-20	1.260 32.0					
8 A.W.G. 8 mm ²	BNYT8 ◇	1.457 37.0	.272 6.9	.181 4.6	COPPER TUBULAR	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	500
6 A.W.G. 6 mm ²	BNYT14 ◇	1.811 46.0	.417 10.6	.346 8.8	COPPER TUBULAR	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	500
4 A.W.G. 22 mm ²	BNYT22 ◇	2.126 54.0	.512 13.0	.441 11.2	COPPER TUBULAR	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
2 A.W.G. 38 mm ²	BNYT38 ◇	2.205 56.0	.587 14.9	.516 13.1	COPPER TUBULAR	K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	500



ALL LISTED

◇ : NOT UL AND C-UL AND CSA CERTIFIED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[BNYT0.5](#) [BNYT1](#) [BNYT2](#) [BNYT5](#)