

DIN 46237

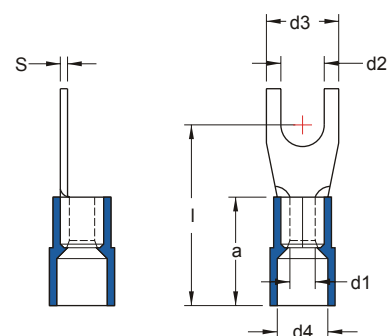
NYLON-INSULATED SPADE TERMINALS

MAXIMUM ELECTRIC CURRENT:

A.W.G.	26	24	22	20	18	16	14	12	10
AMP.	5.5	7	9	12	17	18	30	35	50

MAXIMUM ELECTRICAL RATING: 105°C 600 VOLTS MAX.
INSULATION MATERIAL: NYLON **TERMINAL MATERIAL: COPPER**
INSULATION COLOR:

 26-22 A.W.G.: YELLOW 22-16 A.W.G.: RED 16-14 A.W.G.: BLUE

 12-10 A.W.G.: YELLOW


WIRE RANGE A.W.G. mm ²	ITEM NO.		STUD SIZE		DIMENSION mm						CRIMPING TOOL	Q'TY BOX
	BRAZED SEAM	BUTTED SEAM	d2		d3	l	d1	d4	a	S		
26-22 A.W.G. 0.2-0.5 mm ²	DSNYB2-0.5	DSNY2-0.5	#2	2.2	5.0	12.0	1.0	2.3	8.0	0.5	K.S. MODEL LY8-067 WITH DIE INDEX NO:0.5	1000
	DSNYB3-0.5	DSNY3-0.5	#4	3.2								1000
	DSNYB3.5-0.5	DSNY3.5-0.5	#6	3.7	6.0	15.0						1000
	DSNYB4-0.5	DSNY4-0.5	#8	4.3	6.5							1000
	DSNYB5-0.5	DSNY5-0.5	#10	5.3	8.0							1000
22-16 A.W.G. 0.5-1.5 mm ²	DSNYB3-1	DSNY3-1	#4	3.2	6.0	17.0	1.6	4.0	11.0	0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:RED OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:RED	1000
	DSNYB3.5-1	DSNY3.5-1	#6	3.7								1000
	DSNYB4-1	DSNY4-1	#8	4.3	6.8	18.0						1000
	DSNYBL4-1	DSNYL4-1	#8	4.3	8.0							1000
	DSNYB5-1	DSNY5-1	#10	5.3	10.0	19.0						1000
	DSNYB6-1	DSNY6-1	1/4	6.5	11.0	21.0						1000
16-14 A.W.G. 1.5-2.5 mm ²	DSNYB3-2.5	DSNY3-2.5	#4	3.2	5.5	19.0	2.3	4.5	11.0	0.8	IZUMI MODEL 34 WITH DIE INDEX COLOR:BLUE OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:BLUE	1000
	DSNYB3.5-2.5	DSNY3.5-2.5	#6	3.7	6.0	17.0						1000
	DSNYB4-2.5	DSNY4-2.5	#8	4.3	6.8	18.0						1000
	DSNYBL4-2.5	DSNYL4-2.5	#8	4.3	8.0							1000
	DSNYB5-2.5	DSNY5-2.5	#10	5.3	10.0	20.0						1000
	DSNYB6-2.5	DSNY6-2.5	1/4	6.5	11.0	22.0						1000
12-10 A.W.G. 2.5-6 mm ²	DSNYB4-6	DSNY4-6	#8	4.3	8.0	21.0	3.6	6.4	13.0	1.0	IZUMI MODEL 5 WITH DIE INDEX COLOR:YELLOW OR K.S. MODEL KST2000A HRI-126J WITH DIE INDEX COLOR:YELLOW	500
	DSNYB5-6	DSNY5-6	#10	5.3	10.0	22.0						500
	DSNYB6-6	DSNY6-6	1/4	6.5	11.0	23.0						500
	DSNYB8-6	DSNY8-6	5/16	8.4	14.0	26.0						500
	DSNYB10-6	DSNY10-6	3/8	10.5	18.0	28.0						500

UL cUL ALL LISTED

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

KS Terminals:

[DSNYB10-6](#) [DSNYB2-0.5](#) [DSNYB3.5-0.5](#) [DSNYB3.5-1](#) [DSNYB3.5-2.5](#) [DSNYB3-0.5](#) [DSNYB3-1](#) [DSNYB3-2.5](#)
[DSNYB4-0.5](#) [DSNYB4-1](#) [DSNYB4-2.5](#) [DSNYB4-6](#) [DSNYB5-1](#) [DSNYB5-2.5](#) [DSNYB5-6](#) [DSNYB6-1](#) [DSNYB6-2.5](#)
[DSNYB6-6](#) [DSNYB8-6](#) [DSNYBL4-1](#) [DSNYBL4-2.5](#)