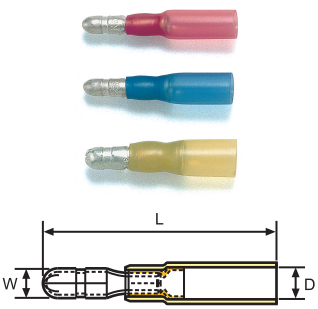
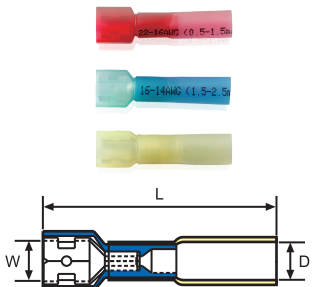


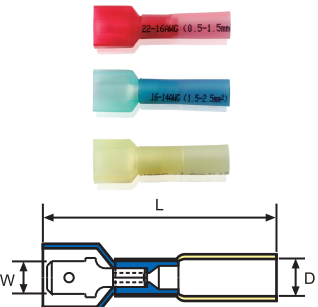
PE-HEAT SHRINKABLE-BULLET DISCONNECTS “HD” (DOUBLE CRIMP TYPE)

	WIRE RANGE A.W.G. / MM ²	ITEM NO.	W	D	L	INSULATED COLOR
	22-16 / 0.5-1.5	MPHD1-156	4.0	5.5	33.0	RED
	16-14 / 1.5-2.5	MPHD2-156	4.0	6.0	33.0	BLUE
		MPHD2-195	5.0			
	12-10 / 4-6	MPHD5-196	5.0	8.1	35.5	YELLOW

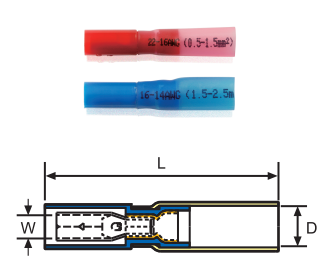
PE-HEAT SHRINKABLE-FULLY NYLON FEMALE DISCONNECTS “H” (TUBULAR TYPE)

	WIRE RANGE A.W.G. / MM ²	ITEM NO.	NEMA TAB IN mm	W	D	L	INSULATED COLOR
	22-16 / 0.5-1.5	FDFNYH 1-250	.032 x .250 0.8 x 6.35	6.6	6.5	36.5	RED
	16-14 / 1.5-2.5	FDFNYH 2-250					BLUE
	12-10 / 4-6	FDFNYH 5-250			7.5	37.0	YELLOW

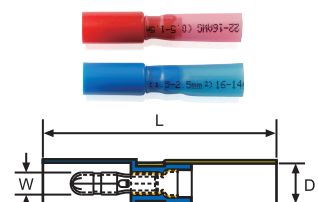
PE-HEAT SHRINKABLE-FULLY NYLON MALE DISCONNECTS “H” (SINGLE CRIMP TYPE)

	WIRE RANGE A.W.G. / MM ²	ITEM NO.	NEMA TAB IN mm	W	D	L	INSULATED COLOR
	22-16 / 0.5-1.5	MDFNYH 1-250	.032 x .250 0.8 x 6.35	6.35	6.5	38.5	RED
	16-14 / 1.5-2.5	MDFNYH 2-250				39.5	BLUE
	12-10 / 4-6	MDFNYH 5-250			7.5		YELLOW

PE-HEAT SHRINKABLE-FULLY NYLON RECEPTACLE DISCONNECTS “HD” (DOUBLE CRIMP TYPE)

	WIRE RANGE A.W.G. / MM²	ITEM NO.	W	D	L	INSULATED COLOR
	22-16 / 0.5-1.5	FRFNYDH1-156	3.9	6.5	40.5	RED
	16-14 / 1.5-2.5	FRFNYDH2-156		7.5		42.5
		FRFNYDH2-195	4.9			

PE-HEAT SHRINKABLE-FULLY NYLON BULLET DISCONNECTORS “HD” (DOUBLE CRIMP TYPE)

	WIRE RANGE A.W.G. / MM ²	ITEM NO.	W	D	L	INSULATED COLOR
	22-16 / 0.5-1.5	MPFNYDH1-156	4.0	6.3	42.0	RED
	16-14 / 1.5-2.5	MPFNYDH2-156		7.3		BLUE

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[KS Terminals:](#)

[FDFNYH1-250](#) [FDFNYH2-250](#) [FDFNYH5-250](#)