

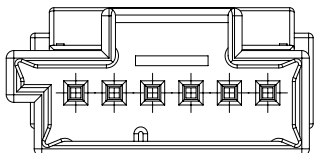
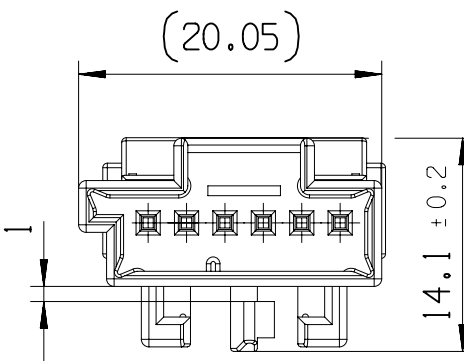
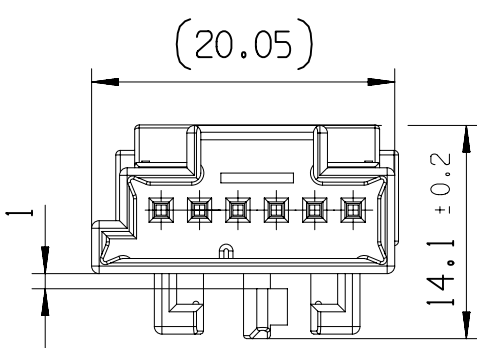
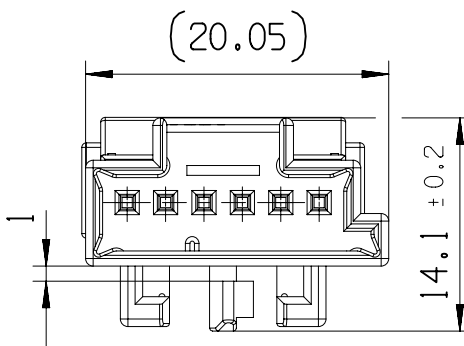
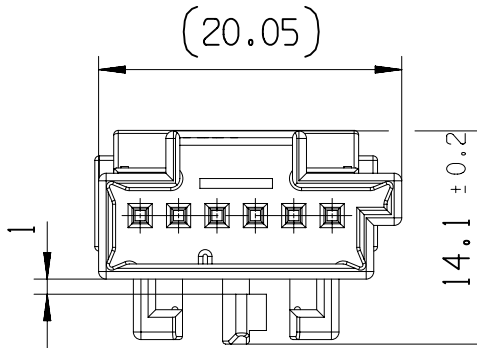
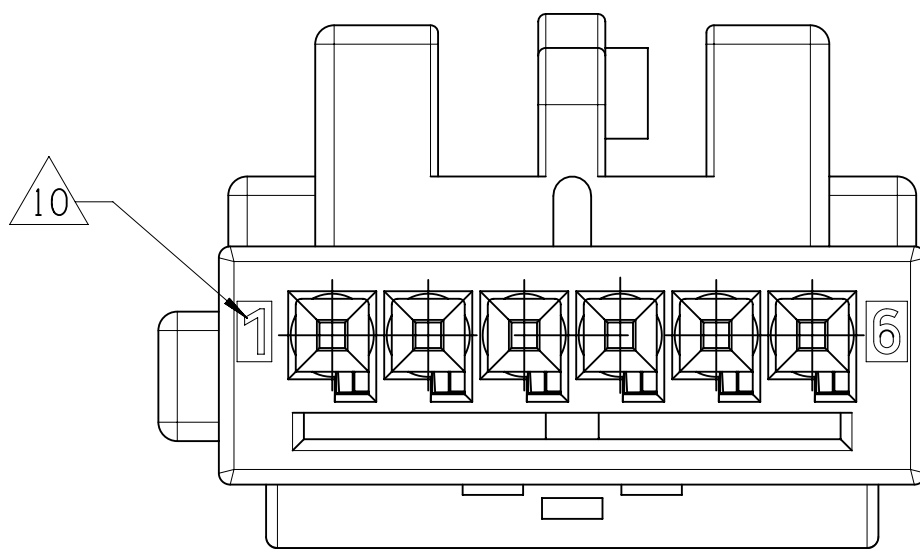


	12		11		
	TAB HOUSING 6 WAY OPTION 1		TAB HOUSING 6 WAY OPTION 2		
	APTIV P/N	CODING	APTIV P/N	CODING	
H	13570116	CODING - A	13543943	CODING - A	
					
G			13744556	CODING - B	
					
F			13931005	CODING - C	
					
E			33183063	CODING - D	
					

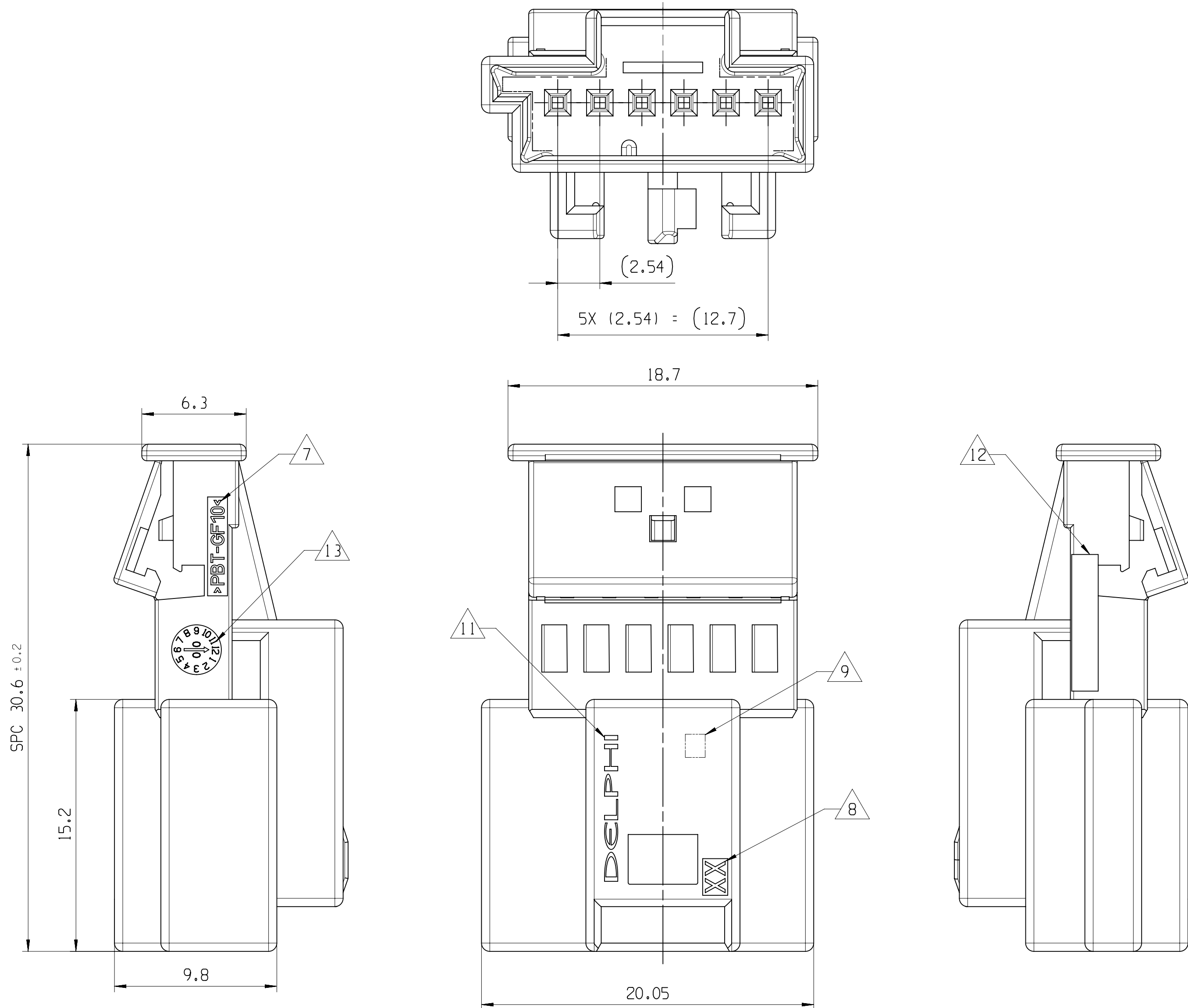

NOTE	SPECIFICATIONS
1	MALE CONNECTOR ACCORDING TO APTIV SPECIFICATION: CAQE TBD
2	MALE CONNECTOR ACCORDING TO: - TEMPERATURE CLASS TX - ENGINE VIBRATOR CLASS VX - SEALING CLASS EX
3	USER'S MANUAL: 13543944-CUS74
4	DELIVERY CONNECTOR WEIGHT : SEE TABLE
5	NO WAFER HINGE OR WAFER HINGE BROKEN ALLOWED
6	VISUAL DEFECTS ON NO FUNCTIONNAL AREAS ALLOWED
⚠	MATERIAL NAME
⚠	TOOL CAVITY NUMBER
⚠	INDEX REPLACEMENT INSERT
⚠	PART CAVITY NUMBER
⚠	SUPPLIER LOGO
⚠	REPLACEMENT INSERT BLANK
⚠	DATE INSERT

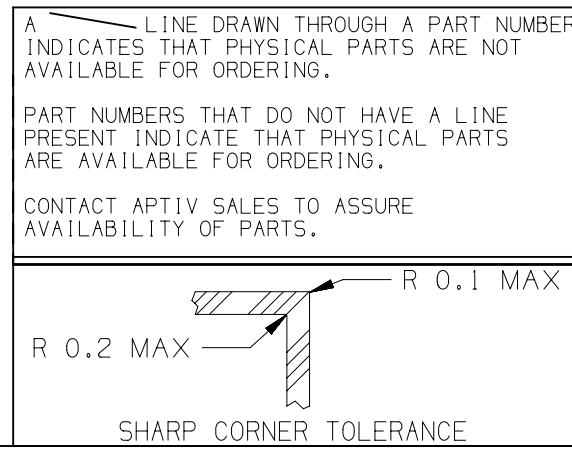

		DIMENSIONAL RANGE (MM)				CHART E1				
☐ DIM TO CHECK	FROM	> 0	> 20	> 30	> 70	> 100	> 150	> 200	> 250	> 300
☐ DIM FOR HELP	TO	20	30	70	100	150	200	250	300	400
TOLERANCE UNLESS OTHERWISE SPECIFIED										
☐ THEORETIC DIM		+0.15	+0.2	+0.3	+0.4	+0.5	+0.6	+0.8	+1	+1.2
ANGULAR TOLERANCE +2°										

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[33183063](#)