

Crimp - Validation

APN: 10811291
 Material: CUCRNISITI
 Surface: SN
 Material Thickness: 0.35 mm
 Cross Section [mm²]: 1.50 | 2.50

FRAMATOME 60040441

Strip Length: 5.00 mm
 Cable Type: FLRY-B

**Uncontrolled
Copy**
For Information only!

Isolation Range Φ [mm]: 2.20-3.00
 Seal : 15443869


Cable type	Seal APN	Struct. nxd [mm]	Insul. diam [mm]	Tear-out force [N]	CCH [mm]	CCH tol. [±mm]	CCW [mm]	CCW tol. [±mm]	ICH [mm]	ICH tol. [±mm]	ICW [mm]	ICW tol. [±mm]
FLRY-B 1.50	15443869	30x0.26	2.30	200	1.70	+ 0.05 - 0.05	2.85	+ 0.10 - 0.10	4.70	+ 0.10 - 0.10	4.80	+ 0.10 - 0.10
FLRY-B 2.50	15443869	50x0.26	2.85	250	1.90	+ 0.05 - 0.05	2.90	+ 0.10 - 0.10	4.80	+ 0.10 - 0.10	5.05	+ 0.10 - 0.10


Core:
 C-2.75-4.0-19
 APN 10713073

Isolation:
 IS-5.00-2.5-19
 APN 10739694

Anvil:

Two piece anvil:
 AC-2.75-4.25
 APN 10764212
 AI-5.00-3.4-0.8
 APN 10805706

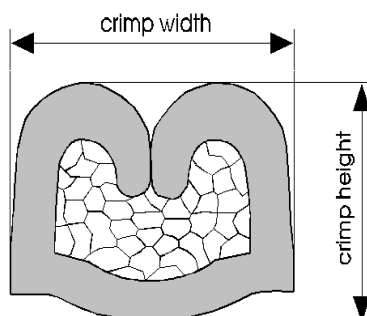


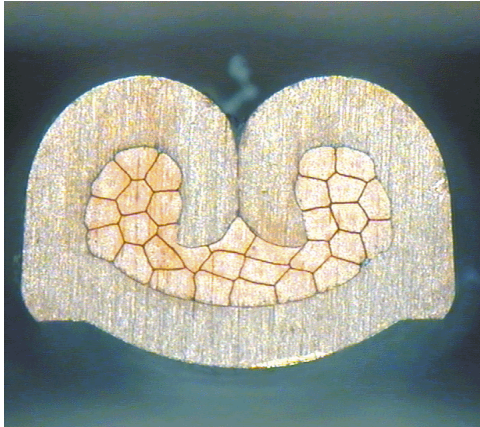

Cable:
FLRY-B 1.50mm² = 30x0.26 mm

Crimp height:
1.70 mm

Crimp width:
2.85 mm

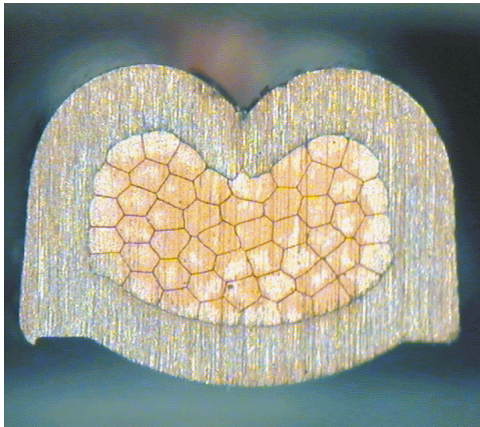

Cable:
FLRY-B 2.50mm² = 50x0.26 mm

Crimp height:
1.90 mm

Crimp width:
2.90 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[10811291](#)