

product: DELPHI PN 15345111  
 material: CUNI3SI1MG  
 surface: AU  
 material thickness: 0,25 mm  
 cross section [mm<sup>2</sup>]: 0,75

strip length: 3,50 mm  
 cable type: FLRY-B  
 insulation Ø [mm]: 1,70 - 1,90  
 seal:

**Uncontrolled  
Copy**  
For Information only!


conductor dimension					crimp dimension [mm]					
cable type	cross sect. [mm <sup>2</sup> ]	struct. n x d [mm]	insul. diam. [mm]	tear-out force [N]	core		insulation			
					height ± 0,05	width ± 0,10	height ± 0,10	width ± 0,10	height ± tol.	width ± tol.
FLRY-B	0,75	24 x 0,21	1,80	120	1,20	1,65	2,00	2,05		

core:  
C-1.60-2.5-10  
DPN 10713763

insulation:  
IS-2.00-2.0-12  
DPN 10803481

anvil:

two piece anvil:  
AC-1.60-2.75-A  
DPN 10764132  
AI-2.00-2.8-0.2  
DPN 10804102

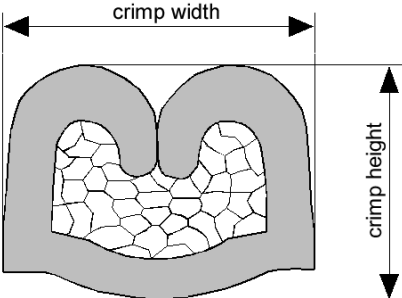

DELPHI PN 15345111



cable:

$0,75 \text{ mm}^2 = 24 \times 0,21 \text{ mm}$

crimp height:

1,20 mm

crimp width:

1,65 mm

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Aptiv:](#)

[15345111](#)