
 




Handle Diameter

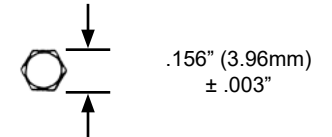

Pin Diameter



 Pin Tip Diameter

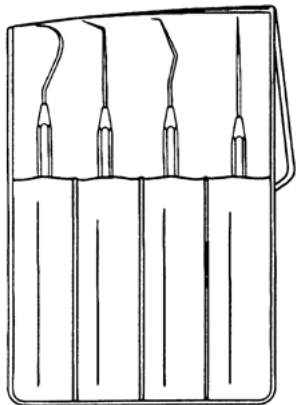

Properties	Typical Value
Material	300 series stainless steel
Handle Diameter	.156" (3.96mm) ± .003"
Points	Semi hardened - may be reshaped for special applications as required
Pin Diameter	.048" (1.22mm) ± .001"
Pin Tip Diameter	.010" - .020" (.254mm - .508mm) ± .001"

Item 35630 - Kit of all four probers in light blue vinyl pouch with individual pockets.



Unless otherwise noted, tolerance is ±5%
Specifications and procedures subject to change without notice.

Prober, Stainless Steel, Hook

3651 WALNUT AVE., CHINO, CA 91710
PHONE: (909) 627-2453
WEBSITE: MendaPump.com

DRAWING NUMBER
35123

DATE:
August 2019

MENDA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Menda:](#)

[35123](#)