

**ebm-papst St. Georgen GmbH & Co. KG**

Hermann-Papst-Str. 1

D-78112 St. Georgen

Phone +49 (0) 7724 81-0

Fax +49 (0) 7724 81-1309

info2@de.ebmpapst.com

www.ebmpapst.com

**Nominal data**

| Type                     | 414 JH            |          |
|--------------------------|-------------------|----------|
| Nominal voltage          | VDC               | 24       |
| Nominal voltage range    | VDC               | 18 .. 27 |
| Speed (rpm)              | min <sup>-1</sup> | 11700    |
| Power consumption        | W                 | 3.0      |
| Min. ambient temperature | °C                | -20      |
| Max. ambient temperature | °C                | 70       |
| Air flow                 | m <sup>3</sup> /h | 22       |
| Sound power level        | B                 | 5.8      |
| Sound pressure level     | dB(A)             | 43       |

ml = Max. load · me = Max. efficiency · fa = Free air · cs = Customer specification · ce = Customer equipment  
Subject to change




**Technical description**

|                                                |                                                        |
|------------------------------------------------|--------------------------------------------------------|
| <b>Weight</b>                                  | 0.050 kg                                               |
| <b>Dimensions</b>                              | 40 x 40 x 25 mm                                        |
| <b>Impeller material</b>                       | Glass-fiber reinforced PA plastic                      |
| <b>Housing material</b>                        | Glass-fiber reinforced PBT plastic                     |
| <b>Airflow direction</b>                       | Exhaust over struts                                    |
| <b>Direction of rotation</b>                   | Counterclockwise, viewed toward rotor                  |
| <b>Storage</b>                                 | Ball bearing                                           |
| <b>Service life L10 at 40 °C</b>               | 60000 h                                                |
| <b>Service life L10 at maximum temperature</b> | 30000 h                                                |
| <b>Cable</b>                                   | Leads AWG 26, TR 64, stripped and tin-plated.          |
| <b>Motor protection</b>                        | Protection against reverse polarity and blocked rotor. |
| <b>Approval</b>                                | VDE, CSA, UL                                           |
| <b>Option</b>                                  | Speed signal                                           |

[illegible]

## Curves: Air performance

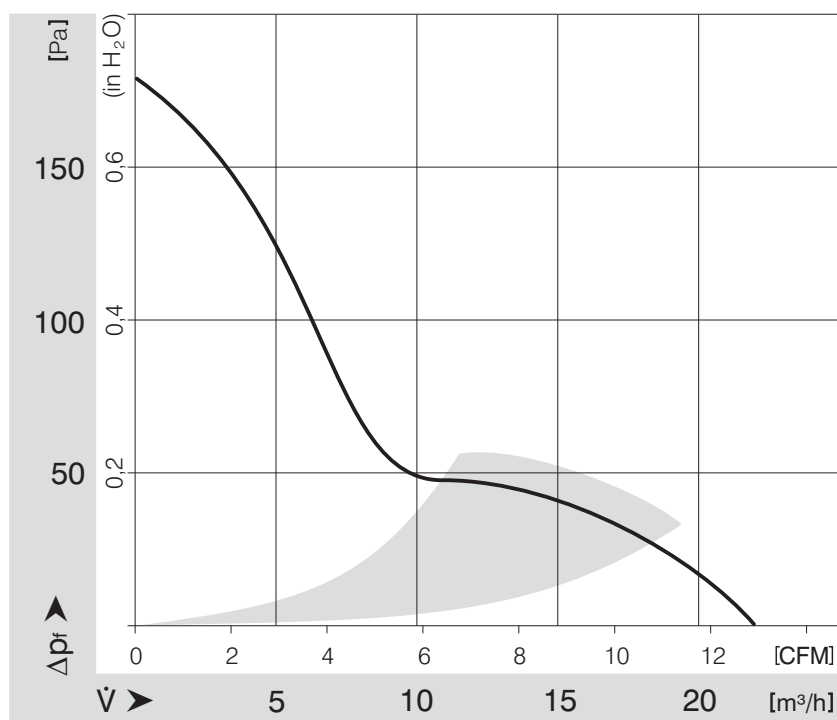

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ebm-papst:](#)

[414JH](#)