



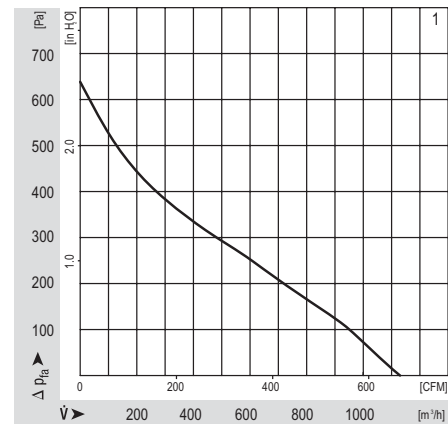

Ø 225mm Backward Curved

- These centrifugal fans have backward curved blades offering an extremely good aerodynamic efficiency
- Impeller completely made of plastic PA 6.6, injection-molded round sheet-metal plate.
- Wiring connection: Red = + ; Blue = - ; White = Tach Output; Yellow = Speed Control
- Integrated electronics with reverse polarity and locked-rotor protection. Rotation is CW Tach Output. Cable exit: variable.
- UL, CSA, VDE approvals on most models, please contact application engineering.
- Recommended inlet ring: 96358-2-4013.

Part Number	Curve	CFM @ 0	VDC	Volt. Range	Power (W)	dBA	Max Amb. Temp. C	Impeller Material	Speed (RPM)	Wgt. (lbs)
R1G225-AF07-52	1	663	24	16 to 28	100	67	60	Plastic	2600	3.31
R1G225-AF11-52	1	665	48	36 to 57	95	67	60	Plastic	2700	3.31

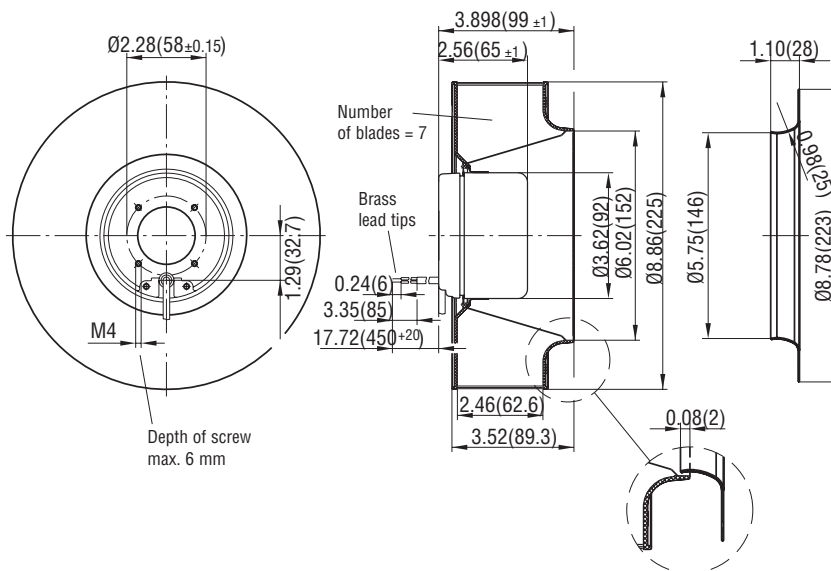

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ebm-papst:](#)

[R1G225-AF07-52](#) [R1G225-AF11-52](#) [R1G225-AC73-38](#) [R1G225-AE07-11](#) [R1G225-AF03-31](#)