

Suggested Panel Cutout

Surface Mount Version

Right Angle Version

FEATURES:

- Through Hole, Right Angle, and SMT Option
- Tape and Reel Packaging

SPECIFICATIONS:

RATING: 25mA 24VDC (Switching)
100mA 50VDC (Non-switching)

TEMPERATURE: -25°C to 80°C (Operating)
-40°C to 85°C (Storage)

ELECTRICAL LIFE: 15,000 Cycles

DIELECTRIC STRENGTH: 250VAC for 1 Minute

INSULATION RESISTANCE: 100MΩ Min. at 250VDC

CONTACT RESISTANCE: 100mΩ Max.


CAPACITANCE: 5pF

VIBRATION TEST: Mil-Std-202F Method 201A


SHOCK TEST: Mil-Std-202F Method 213B

OPERATION FORCE: 200gf-cm

Actuator Options

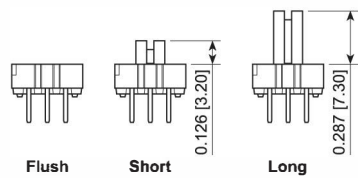


Terminal Options

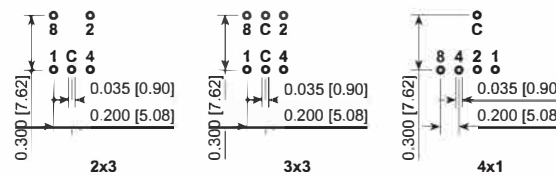

DR3MH-10R



DR2-10R

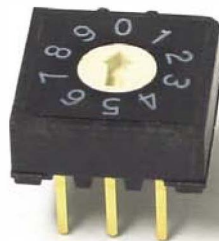

DR3-10R



DR4A-16R

Series	Terminal Type	Actuator Type	Number of Positions	Encoding Type	Packaging
DR2 - 2x3 Terminal Pattern	None - Through Hole	None - Flush	10 - 10 Positions	R - Real Codes	None - Bulk
DR3 - 3x3 Terminal Pattern	A - Right Angle	H - Long	16 - 16 Positions		B - Tube
DR4 - 4x1 Terminal Pattern	M - Surface Mount	S - Short (*)			TR - Tape and Reel (**)
	N - Snap-In Through Hole				

Notes:
* = Available with 3x3 Terminal Pattern Only.
** = Available with Surface Mount Terminals Only

EXAMPLE PART NUMBERS:

- DR2-10R** 10 Position
2x3, Through Hole, Flush, Real Code
- DR3-10R** 10 Position
3x3, Through Hole, Flush, Real Code
- DR3-16R** 16 Position
3x3, Through Hole, Flush, Real Code
- DR3A-10R** 10 Position
3x3, Right Angle, Flush, Real Code
- DR3AH-10R** 10 Position
3x3, Right Angle, Long, Real Code
- DR3H-10R** 10 Position
3x3, Through Hole, Long, Real Code
- DR3H-16R** 16 Position
3x3, Through Hole, Long, Real Code
- DR3M-10R** 10 Position
3x3, SMT, Flush Actuator, Real Code



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[DR3A-16R-B](#) [DR75-AMSF-10R-TR](#) [DR75-AMSF-10R-B](#) [DR3M10RTR](#) [DR2MS16RTR](#)