

 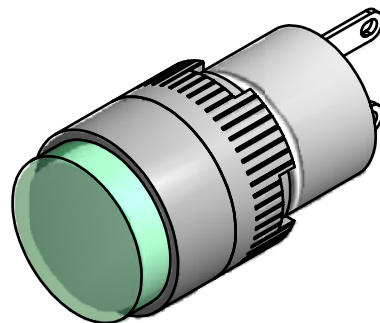
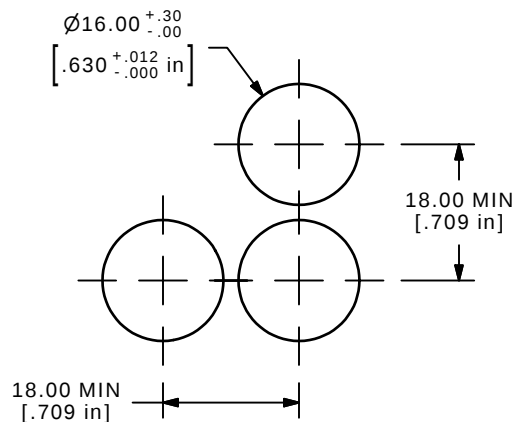




PARTS LIST			
ITEM	QTY	PART NUMBER	DESCRIPTION
1	1	F040003	L16PL10 BODY
2	1	F050112	50-001-12 GREEN FLAT TRANSPARENT LENS (ROUND)
3	1	F050413	50-004-13 GREEN NEON 220 VAC



RECOMMENDED PANEL MOUNTING

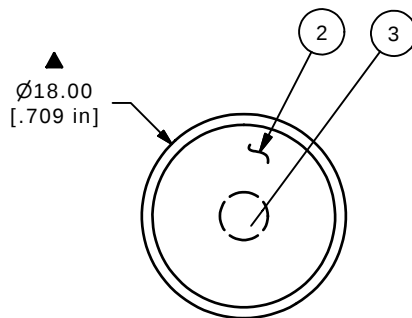

CIRCUIT

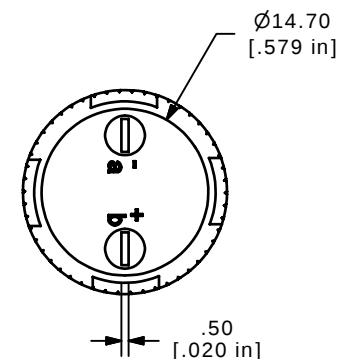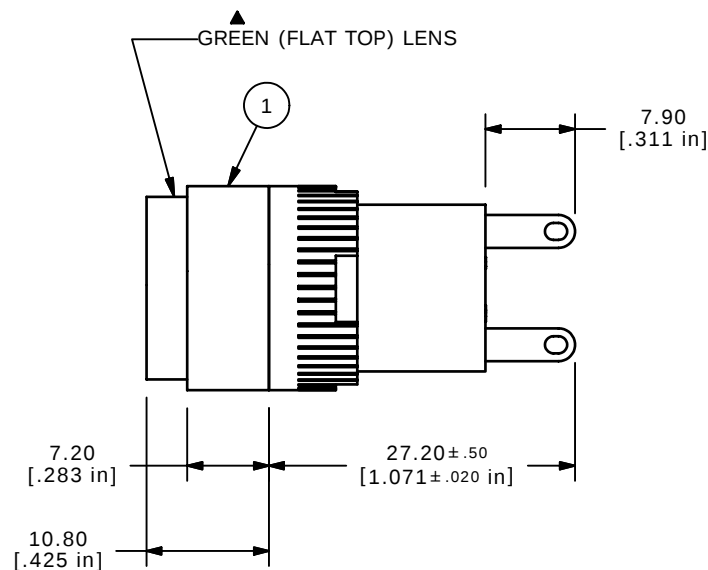

NOTE:

1. ALL DIMENSIONS IN MM [INCH]
2. GENERAL TOLERANCE: X.X=±0.4
X.XX=±0.25
3. TERMINAL NUMBERS FOR REF ONLY
4. OPERATING TEMP: -25°C to +55°C
5. STORAGE TEMP: -40°C TO +85°C
- ▲ 6. LAMP VOLTAGE: 220VAC NEON GREEN
7. SEAL: PROTECTED TO IP40.
8. PANEL THICKNESS: 0.5 - 5.0 mm
9. PACKAGE: 20 PER BOX
10. ▲ DENOTES CRITICAL PARAMETER.
11. 2002/95/EC (ROHS) COMPLIANT.



E-SWITCH®



TITLE L16PLR10GGRNGRN

A	18505	RELEASED FOR PRODUCTION	5/6/09	BLR
REV	PCR NO	DESCRIPTION	DATE	BY

THE INFORMATION CONTAINED IN THIS DOCUMENT IS PROPRIETARY
TO E-SWITCH AND IS NOT TO BE COPIED OR TRANSFERRED

SCALE 1.5:1

DATE 5/6/2009

DR	
BLR	

DWG XF0796P

REV
A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[L16PLR10GGRNGRN](#)