

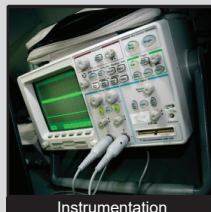


RBW2 SERIES ROCKER SWITCH

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS

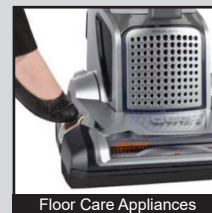

APPLICATIONS / MARKETS

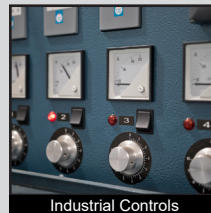

RoHS

SPECIFICATIONS

Electrical Rating: 16(16)A 125VAC 5E4 T85 [cURus]
1/3HP 125VAC IP66 [cURus]

Electrical Life: 50,000 Cycles

Mechanical Life: 50,000 Cycles

Contact Resistance: <30mΩ Max.

Insulation Resistance: 500MΩ Min. at 500VDC

Dielectric Strength: 1,000VAC for 1 Minute

Operating Temperature: -20°C to 85°C

Ingress Protection: IP66

Panel Cutout: 22mm x 30mm

Function: DPST, Off-On DPDT, On-On

FEATURES & BENEFITS

- Full illumination options available
- Approved under new UL 61058-1 rating
- UL approved up to 1/3HP
- Internally sealed to an IP66 rating using patented technology (Patent No.: US 7,872,205 B2)

PART NUMBER CONFIGURATOR

Series

RBW2

Circuit

A - Off-On (DPST)

*B - On-On (DPDT)

Body Color

BLK - Black

WHT - White

Actuator Color

BLK - Black

WHT - White

RIL - Red Full Illumin.

GIL - Green Full Illumin.

YIL - Yellow Full Illumin.

BIL - Blue Full Illumin.

Marking

A - Dot

D - I/O Vertical

F - I/O Vertical

G - I/O Horizontal

I - On/Off Vertical

E - No Marking

Termination

F - 6.3mm Tab

Lamp Voltage

0 - No Lamp

1 - 125VAC Neon

2 - 250VAC Neon

3 - 12VDC Incandescent

* Not available with Illuminaiton

Specifications subject to change without notice 11.16.2021



E-SWITCH®

www.e-switch.com






800.867.2717

1

RBW2 SERIES ROCKER SWITCH

BODY DIMENSIONS






A - CIRCUIT

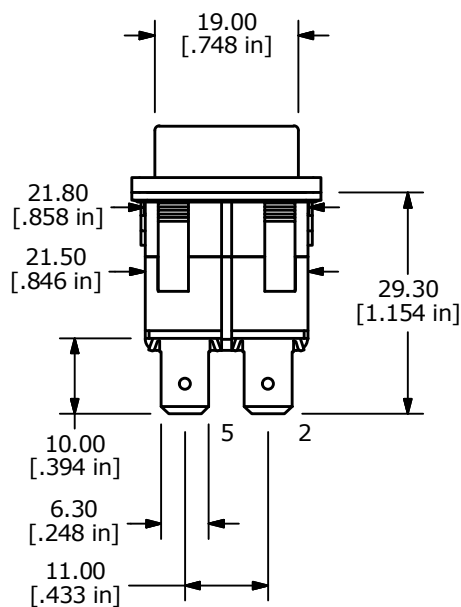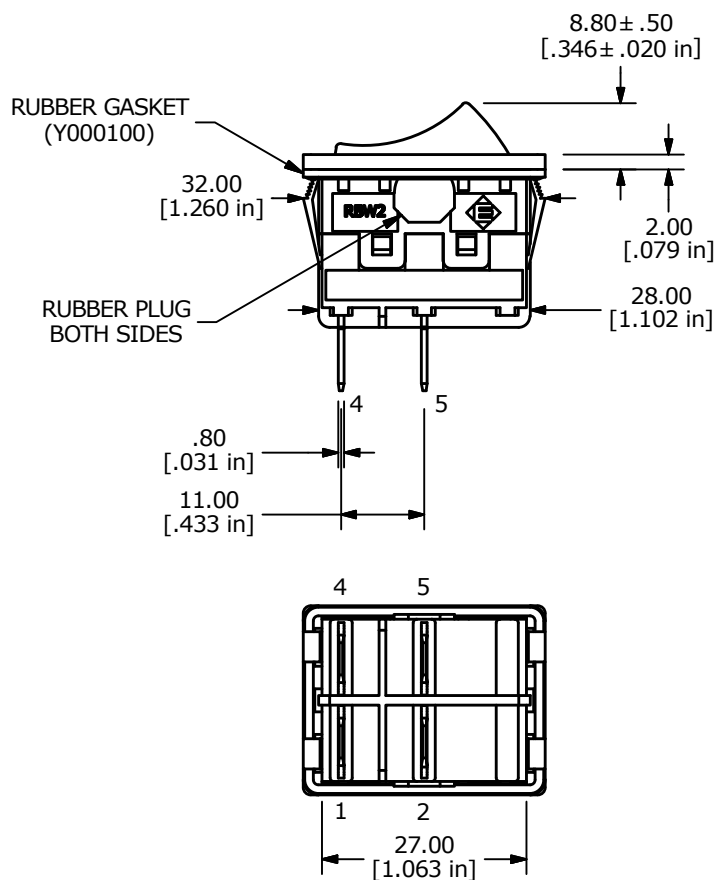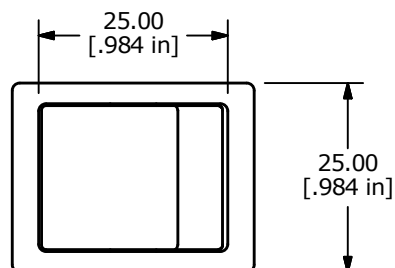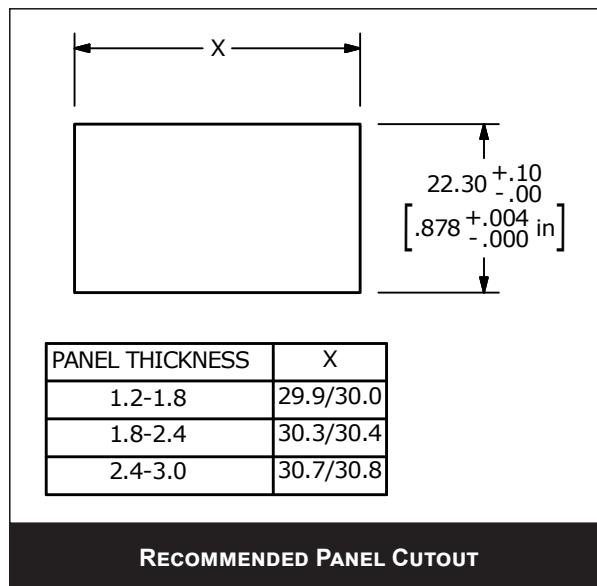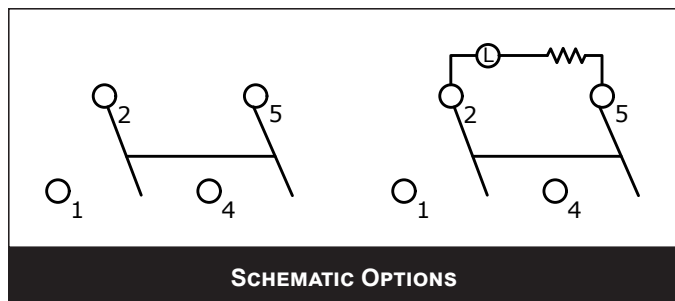

RBW2 SERIES ROCKER SWITCH


BODY DIMENSIONS

B - CIRCUIT

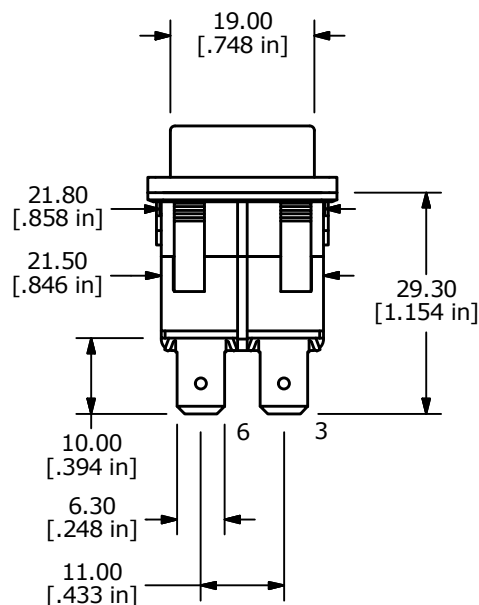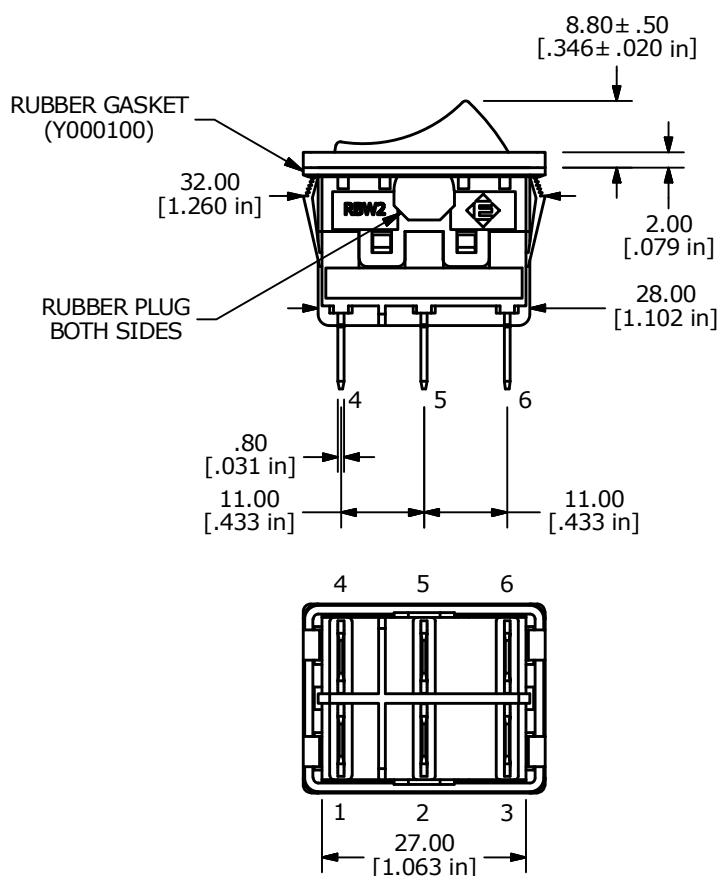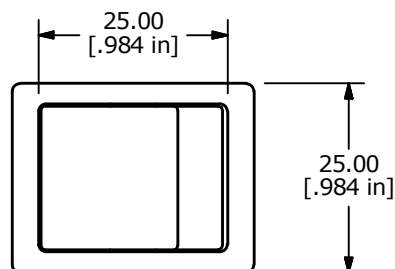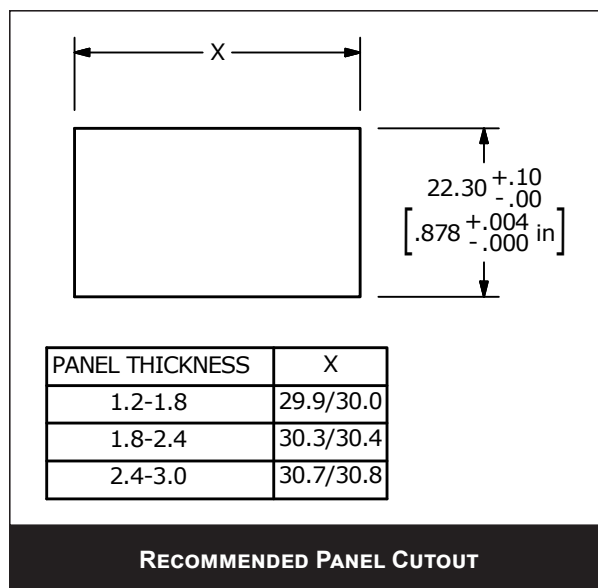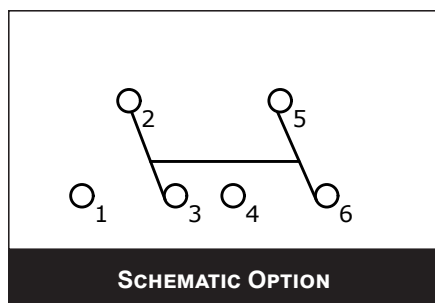


RBW2 SERIES ROCKER SWITCH


MARKING OPTIONS

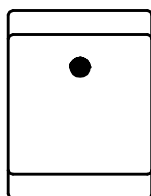


A - Dot

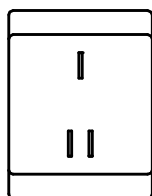


**D - I/II
VERTICAL**

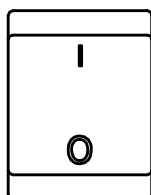


**F - I/O
VERTICAL**

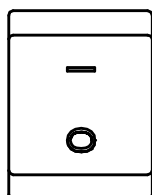

**G - I/O
HORIZONTAL**

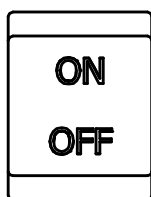

**I - ON/OFF
VERTICAL**

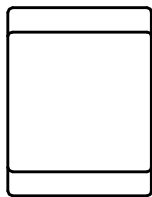

E - No MARKING



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[RBW2ABLKBLKEF0](#) [RBW2ABLKBLKFF0](#) [RBW2ABLKBLKIF0](#) [RBW2ABLKGILFF1](#) [RBW2ABLKREDIF0](#)
[RBW2ABLKRIILFF1](#) [RBW2BBLKBLKEF0](#) [RBW2BBLKREDEF0](#) [RBW2ABLKRIILFF2](#) [RBW2ABLKYILFF1](#)
[RBW2ABLKGILFF2](#) [RBW2ABLKRIILF1](#) [RBW2ABLKRIILEF1](#) [RBW2ABLKGILEF1](#) [RBW2ABLKBILEF3](#)
[RBW2ABLKGILGF2](#) [RBW2BBLKBLKDF0](#) [RBW2ABLKRIILFF3](#) [RBW2ABLKGILEF3](#)