



Sealable cover cap for 3RF29 function modules except converter

product brand name	SIRIUS		
product designation	sealable cover		
General technical data			
product function	for function modules 3RF29		
degree of pollution	3		
protection class IP on the front according to IEC 60529	IP20		
shock resistance according to IEC 60068-2-27	15g / 11 ms		
vibration resistance according to IEC 60068-2-6	2g		
Substance Prohibitance (Date)	07/01/2006		
Weight	0.485 g		
Main circuit			
operating frequency rated value	50 ... 60 Hz		
derating temperature	40 °C		
Auxiliary circuit			
number of CO contacts for auxiliary contacts	0		
Installation/ mounting/ dimensions			
fastening method side-by-side mounting	Yes		
fastening method	clip-on		
Electrical Safety			
protection class IP on the front according to IEC 60529	IP20		
touch protection on the front according to IEC 60529	finger-safe, for vertical contact from the front		
Ambient conditions			
installation altitude at height above sea level maximum	1 000 m		
ambient temperature			
• during storage	-55 ... +80 °C		
Electromagnetic compatibility			
conducted interference			
• due to burst according to IEC 61000-4-4	2 kV / 5 kHz behavior criterion 2		
• due to conductor-earth surge according to IEC 61000-4-5	2 kV behavior criterion 2		
• due to conductor-conductor surge according to IEC 61000-4-5	1 kV behavior criterion 2		
• due to high-frequency radiation according to IEC 61000-4-6	140 dBuV in the frequency range 0.15 ... 80 MHz, behavior criterion 1		
electrostatic discharge according to IEC 61000-4-2	4 kV contact discharging / 8 kV air discharging, behavior criterion 2		
conducted HF interference emissions according to CISPR11	Class A for industrial environment		
field-bound HF interference emission according to CISPR11	Class B for the domestic, business and commercial environments		
Approvals Certificates			
General Product Approval		EMV	other



[Confirmation](#)



[Confirmation](#)

## Environment

[Environmental Confirmations](#)

## Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RF2900-0RA88>

Cax online generator


<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RF2900-0RA88>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RF2900-0RA88>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[http://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=3RF2900-0RA88&lang=en](http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RF2900-0RA88&lang=en)

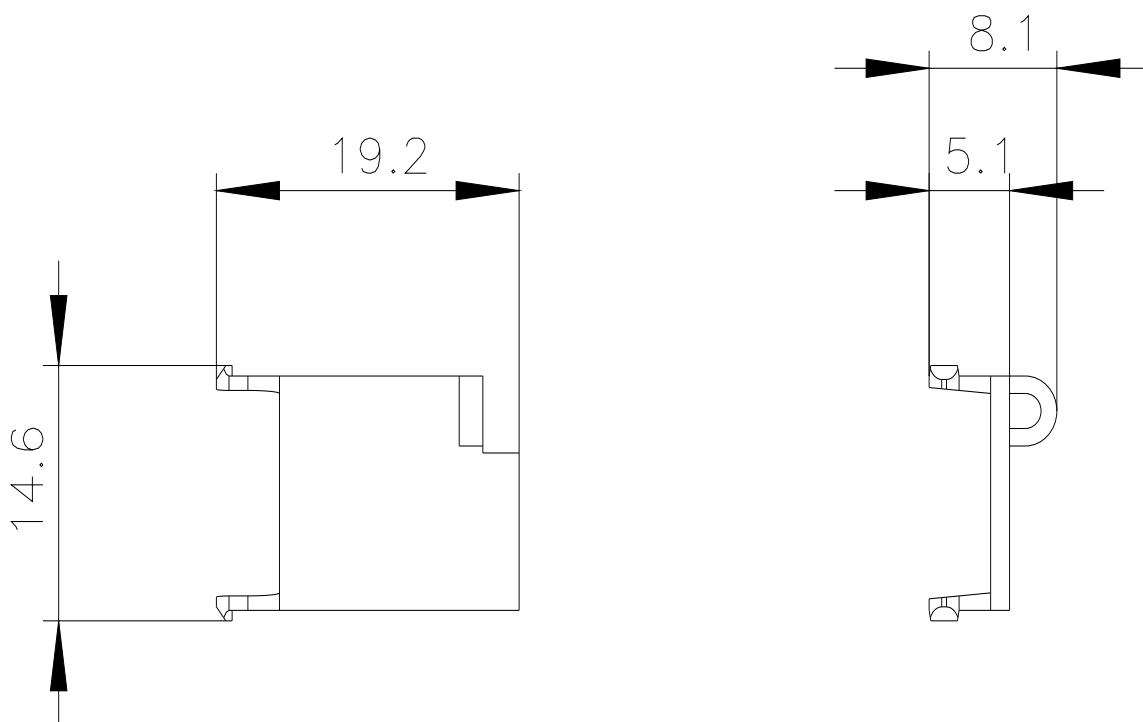

last modified:

3/17/2021

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RF29000RA88](#)