



ID key-operated switch, 22 mm, round, plastic with metal front ring, black, RFID, 4 switch positions O-I-II-III, actuating angle 3x45°, without ID key

|                                                                |                                                                    |
|----------------------------------------------------------------|--------------------------------------------------------------------|
| product brand name                                             | SIRIUS ACT                                                         |
| product designation                                            | ID key-operated switches                                           |
| design of the product                                          | Actuating/signaling element                                        |
| product type designation                                       | 3SU1                                                               |
| product line                                                   | Plastic with metal front ring, matt, 22 mm                         |
| <b>Actuator</b>                                                |                                                                    |
| principle of operation of the actuating element                | latching                                                           |
| product extension optional                                     |                                                                    |
| • light source                                                 | No                                                                 |
| • contact module                                               | No                                                                 |
| color                                                          |                                                                    |
| • of the actuating element                                     | black                                                              |
| material of the actuating element                              | plastic                                                            |
| shape of the actuating element                                 | round                                                              |
| outer diameter of the actuating element                        | 29.5 mm                                                            |
| number of switching positions                                  | 4                                                                  |
| switch position for key distraction                            | Key removal possible in all 4 positions                            |
| <b>Front ring</b>                                              |                                                                    |
| product component front ring                                   | Yes                                                                |
| design of the front ring                                       | Standard                                                           |
| material of the front ring                                     | Metal, matt                                                        |
| color of the front ring                                        | sand gray                                                          |
| <b>General technical data</b>                                  |                                                                    |
| protection class IP                                            | IP65                                                               |
| mechanical service life (operating cycles) typical             | 100 000                                                            |
| reference code according to IEC 81346-2                        | S                                                                  |
| Substance Prohibitance (Date)                                  | 10/01/2014                                                         |
| <b>Connections/ Terminals</b>                                  |                                                                    |
| tightening torque of the screws in the bracket                 | 1 ... 1.2 N·m                                                      |
| <b>Ambient conditions</b>                                      |                                                                    |
| ambient temperature                                            |                                                                    |
| • during operation                                             | -25 ... +70 °C                                                     |
| • during storage                                               | -40 ... +80 °C                                                     |
| environmental category during operation according to IEC 60721 | 3M6, 3S2, 3B2, 3C3, 3K6 (with relative air humidity of 10 ... 95%) |
| <b>Installation/ mounting/ dimensions</b>                      |                                                                    |
| height                                                         | 29.5 mm                                                            |
| width                                                          | 29.5 mm                                                            |
| mounting diameter                                              | 22.3 mm                                                            |
| positive tolerance of installation diameter                    | 0.4 mm                                                             |

|                    |         |
|--------------------|---------|
| mounting height    | 29.6 mm |
| installation width | 29.5 mm |
| installation depth | 29.5 mm |

#### Approvals Certificates

##### General Product Approval



[Confirmation](#)



| General Product Approval | Test Certificates | Marine / Shipping |
|--------------------------|-------------------|-------------------|
|--------------------------|-------------------|-------------------|



[Special Test Certificate](#)

[Type Test Certificates/Test Report](#)



| Marine / Shipping | other |
|-------------------|-------|
|-------------------|-------|



[Confirmation](#)

#### Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3SU1030-4WS10-0AA0>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3SU1030-4WS10-0AA0>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3SU1030-4WS10-0AA0>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[http://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=3SU1030-4WS10-0AA0&lang=en](http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SU1030-4WS10-0AA0&lang=en)

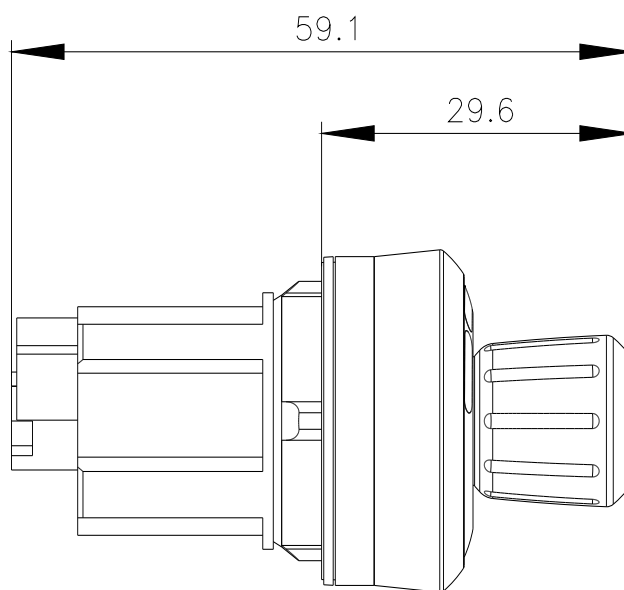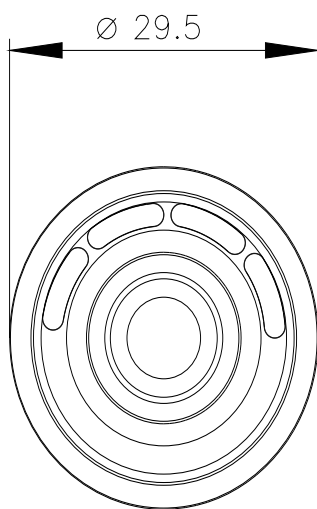

---

last modified:

1/26/2022 

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3SU10304WS100AA0](#)