


## POTENTIAL TERMINAL BLOCK BL.YELL.BR.BL

Art.No.: 56111  
 Weight: 0.079  
 Country of origin: CZ  
 Model designation: Potenzialkbl. blau gelb braun blau

Potential terminal block  
 blue/yellow/brown/blue

### [Link to Product](#)

#### Illustration

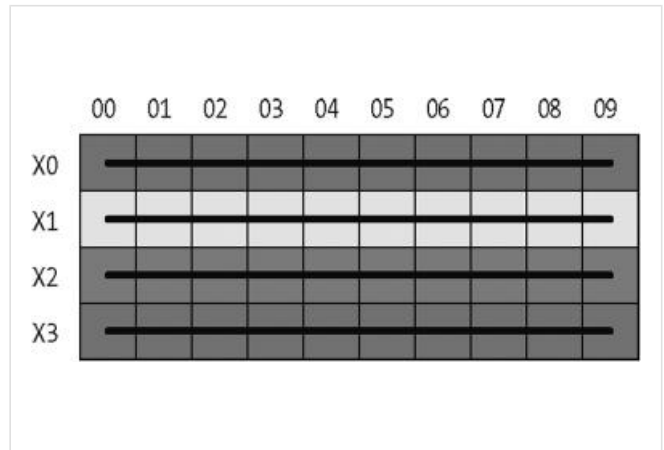

Product may differ from Image



#### Commercial data

ECLASS-6.0	27141106
ECLASS-6.1	27141106
ECLASS-7.0	27141106
ECLASS-8.0	27141106
ECLASS-9.0	27141106
ECLASS-10.1	27141106
ECLASS-11.1	27141106
ECLASS-12.0	27141106
ETIM-5.0	EC001283
customs tariff number	85369010
GTIN	4048879049351
Packaging unit	1

#### Electrical data | Supply

Operating voltage AC max.	30 V
Operating voltage DC max.	30 V
Total current max.	10 A

#### Installation

Connection cross section max.	2,5 mm <sup>2</sup>
AWG number min.	28
AWG number max.	14

**Installation | Connection**

Connection	Spring clamp plug-in terminals
------------	--------------------------------

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP20
-------------------------------------	------

**Mechanical data | Mounting data**

Height	70 mm
Width	56 mm
Depth	32,5 mm

**Environmental characteristics | Climatic**

Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murrelektronik:](#)

[56111](#)