

04520GA (旧BM4520)

Φ45X20^L

DC Blower Fan

General Specifications

Motor Protection Auto Restart / Polarity Protection

Insulation Resistance 10MΩ or over with a DC500V Megger

Dielectric Withstand Voltage: AC700V 1s

Allowable Ambient $-10^{\circ}\text{C} \sim +70^{\circ}\text{C}$ (Operating)


Temperature Range $-40^{\circ}\text{C} \sim +70^{\circ}\text{C}$ (Storage)
non-condensing environment




Outline

Expected Life ※ Failure Rate: 10% (L10 Life)

25°C 50,000 (Hours)

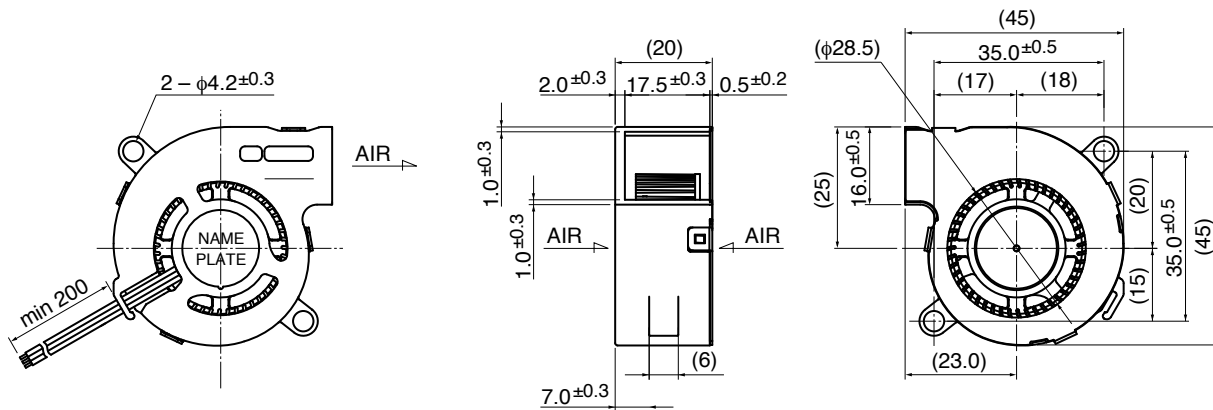

Characteristic Curves

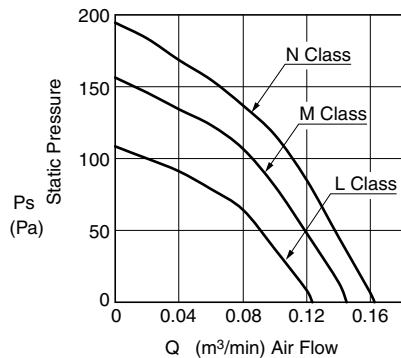

Material

Casing Lower : Plastic (Black) UL94V-0
Casing Upper : Steel
Impeller : Plastic (Black) UL94V-0
Bearing : Ball Bearing
Lead Wire : UL1061 AWG26 + : Red, - : Black

Specifications

Model	Product No.	Rating Voltage	Operating Voltage	Current	Input Power	Speed	Max. Air Flow		Max. Static Pressure		Noise	Mass
		(V)	(V)	(A) ^{*1}	(W) ^{*1}	(min ⁻¹) ^{*1}	(m ³ /min) ^{*1}	(CFM) ^{*1}	(Pa)	(In H ₂ O)	(dB) ^{*1}	(g)
04520GA-12L-AA-	00	12	6.0 ~ 13.8	0.09	1.08	6000	0.12	4.2	100.0	0.40	27.0	25
04520GA-12M-AA-	00			0.15	1.80	7000	0.14	4.9	150.0	0.60	32.0	
04520GA-12N-AA-	00			0.17	2.04	7700	0.16	5.6	190.0	0.76	35.0	

Rotation: Clockwise as seen from the label side

*1: Average Values in Free Air

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[MinebeaMitsumi:](#)

[04520GA-12N-AT-00](#)