


OAT230 / OAT232 Fan Trays

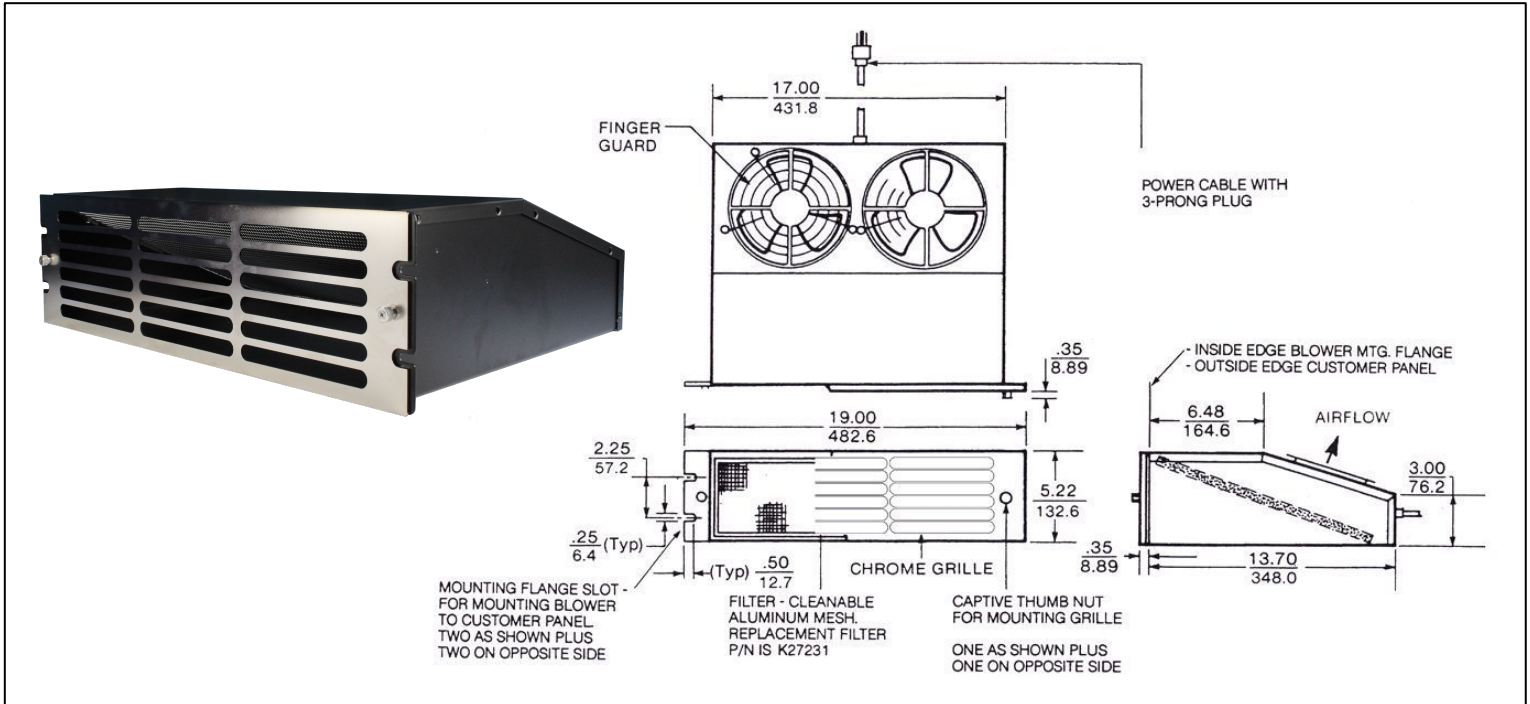

3 RU Fan Tray, 2 Fans
482.6mm x 132.6mm x 356.9mm
(19.00" x 5.22" x 14.05")



Description

- 3 RU High, Rack mount configuration
- Fits in EIA-310-D standard 19" rack enclosures
- Filters are easy to clean and replace using front thumb screw, P/N is K27231 for replacements
- Fixed cord with grounded North American NEMA 5-15P plug
- High Airflow of 400 CFM provided by reliable Orion OA172SAP Axial fans
- Custom speeds and voltages are available on request

Part Number	OAT230	OAT232
Number of Fans	2	2
Bearing System	Ball Bearings	Ball Bearings
Voltage Rating (Volts AC)	115	230
Voltage Range (Volts AC)	90 ~ 130	200 ~ 265
Power Rating (Watts)	70	70
Combined Airflow (CFM)	400	400
Combined Noise (dBA)	57	57
Life Expectancy L10	60,000 Hours @ 25°C	60,000 Hours @ 25°C
Operating Temperature (°C)	-10°C ~ +50°C, 20~90% RH	-10°C ~ +50°C, 20~90% RH
Storage Temperature (°C)	-40°C ~ +85°C, 10~ 95% RH	-40°C ~ +85°C, 10~ 95% RH

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[OAT230](#) [OAT232](#)