


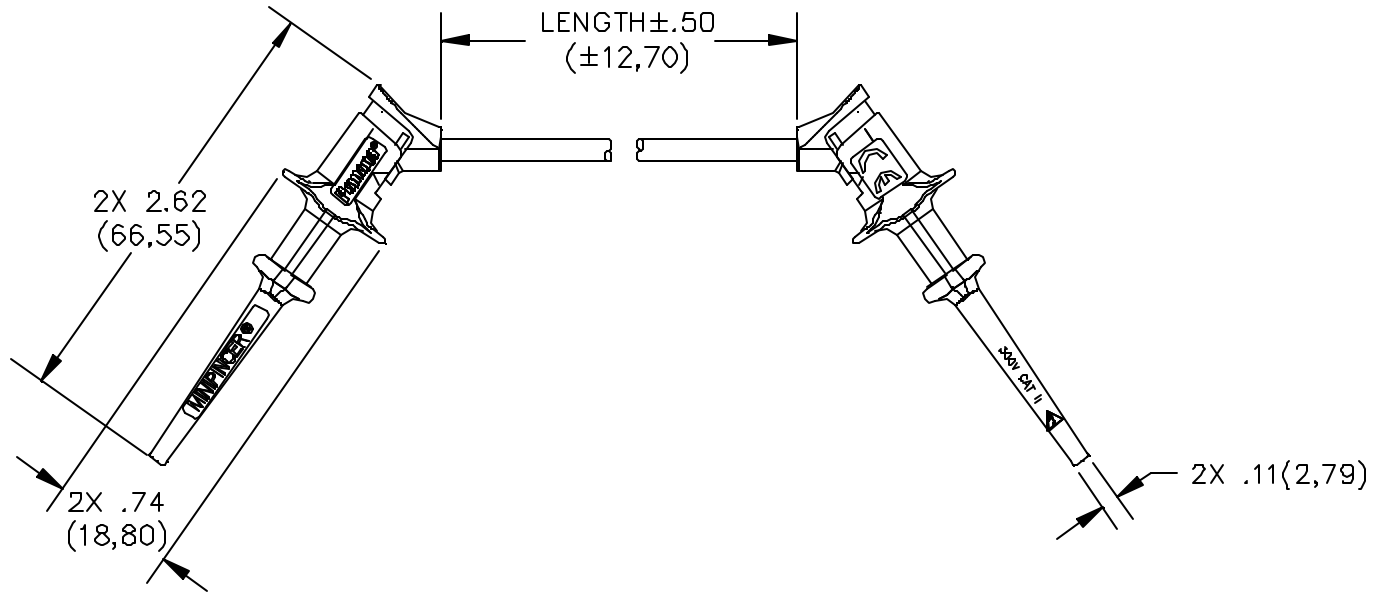

FEATURES:

- Attaches to component leads up to .090" (2.3 mm)
- Complies to IEC1010-2-031 Test Standards
- High strand count silicone insulated wire offers excellent flexibility and high temperature resistance.

MATERIALS:

Pincer: Body: Nylon 6 – Fire Retardant – UL94 V-0 Rated, Color per part number

Pincer Contacts: Beryllium Copper, Gold Plated

Wire: 18 AWG, 65 x 36 t.c., Insulation – Silicone, .144" (3,66 mm) O.D., Color per P/N.

RATINGS:

IEC 1010-2-031

Operating Voltage: 300 V, CAT II, P2

Current: 5 Amperes

ORDERING INFORMATION: Model 6295-XX-*

XX = Length in Inches, Standard Lengths: 12" (305), 24" (610), 36" (914), 48" (1219), 60" (1524)

*= Color Code: -0 Black, -2 Red

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[6295-36-2](#) [6295-36-0](#) [6295-48-2](#) [6295-48-0](#) [6295-24-0](#) [6295-24-2](#) [6295-12-0](#) [6295-12-2](#)