


Kit containing 10 pieces of 5243, one of each color.

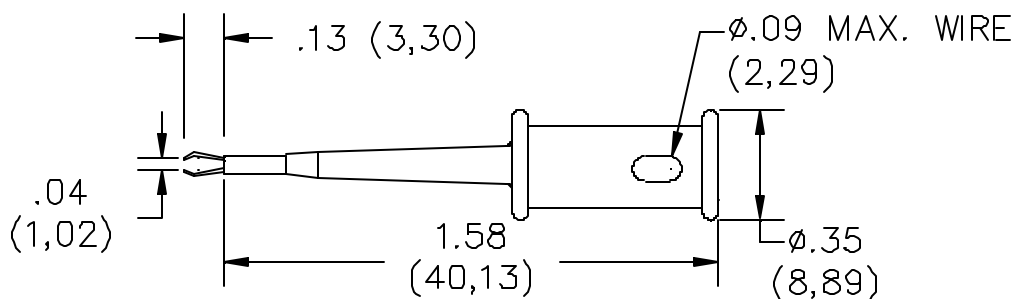

MATERIALS:

Contact – Stainless steel, Type 301, ½ Hard

Spring – Stainless steel, Type 302.

Cap – Glass Filled Nylon.

Marking: “Model 5243”

Barrel – Glass filled nylon. Color: Matches color of cap.

Marking: “POMONA GRABBER®”

Finish: Contact – Gold plated per MIL-G-45204, Type II, 30 to 50 microinches.

RATINGS:

Operating Temperature: +102° C. (+216° F) Max.

Operating Voltage: 30VAC / 60VDC Max.

Current: 0.5 Amperes

ORDERING INFORMATION: Model 5243 & 5520 Kit

Standard Colors: Available in 10 colors: -0 Black, -1 Brown, -2 Red, -3 Orange, -4 Yellow, -5 Green, -6 Blue, -7 Violet, -8 Gray, -9 White

Ordering Example: 5243-2 Color is Red

Ordering 5520 “Kit” – contains one color each of the 5243-.*.

SIMPLIFIED ASSEMBLY PROCEDURE

1. Pull off thumb cap to expose contact connection.
2. Thread wire through thumb cap and strip 3.18 (1/8).
3. Insert stripped end through hole on contact and solder.
4. Slide thumb cap back onto contact.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02” (.51 mm), .xxx = ± .005” (.127 mm).
All specifications are to the latest revisions. Specifications are subject to change without notice.
Registered trademarks are the property of their respective companies.

Made in USA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[5243-02](#) [5243-9](#) [5243-5](#) [5243-1](#) [5243-3](#) [5243-4](#) [5243-7](#) [5243-6](#) [5243-8](#)