

Abox 100 – Polypropylene – 152 x 152 mm (5.98 x 5.98 in.)

Standard Features

- **Protection Level:** IP66
- **Technical:** Self Sealing Soft Elastic Membr
Suitable for Metric Entry
- **Sealing Area:** M20/M25/M32 - 8 to 28mm
- **UL Recognized Enclosure Material:** Polypropylene
- **Gasket Material:** Thermoplastic Elastomer
- **Color:** Light Gray or White
- **Material Operating Temperature Range:** Polypropylene
-25°C to 55°C (-13°F to 131°F)
- **Accessories:** See section below




Abox

Ordering Information	Cat. No.	Color	Screw Terminal	Length	Dimensions mm (in)	Width	Height	Std. Pk.
Enclosure with terminals	810-420-01	gray	10 mm ² - 5 pole	152 mm (5.98 in)	152 mm (5.98 in)	152 mm (5.98 in)	80 mm (3.15 in)	2
Enclosure with terminals	810-120-01	white	10 mm ² - 5 pole	152 mm (5.98 in)	152 mm (5.98 in)	152 mm (5.98 in)	80 mm (3.15 in)	2
Enclosure - empty	810-400-01	gray	NA	152 mm (5.98 in)	152 mm (5.98 in)	152 mm (5.98 in)	80 mm (3.15 in)	2
Enclosure - empty	810-100-01	white	NA	152 mm (5.98 in)	152 mm (5.98 in)	152 mm (5.98 in)	80 mm (3.15 in)	2

Accessories

Ordering Information	Cat. No.	Type	Std. Pk.
Mounting Plate	895-110-01	MPI100	1
DIN Rail TS 35 – 35x120 mm	895-310-01	TS35/120	1
Terminal (high-set)	896-410-01	10 mm ² - 5 pole, 57A/690V	5
Pole Mount Kit (60-170mm)	896-020-01	MABF100-1	1

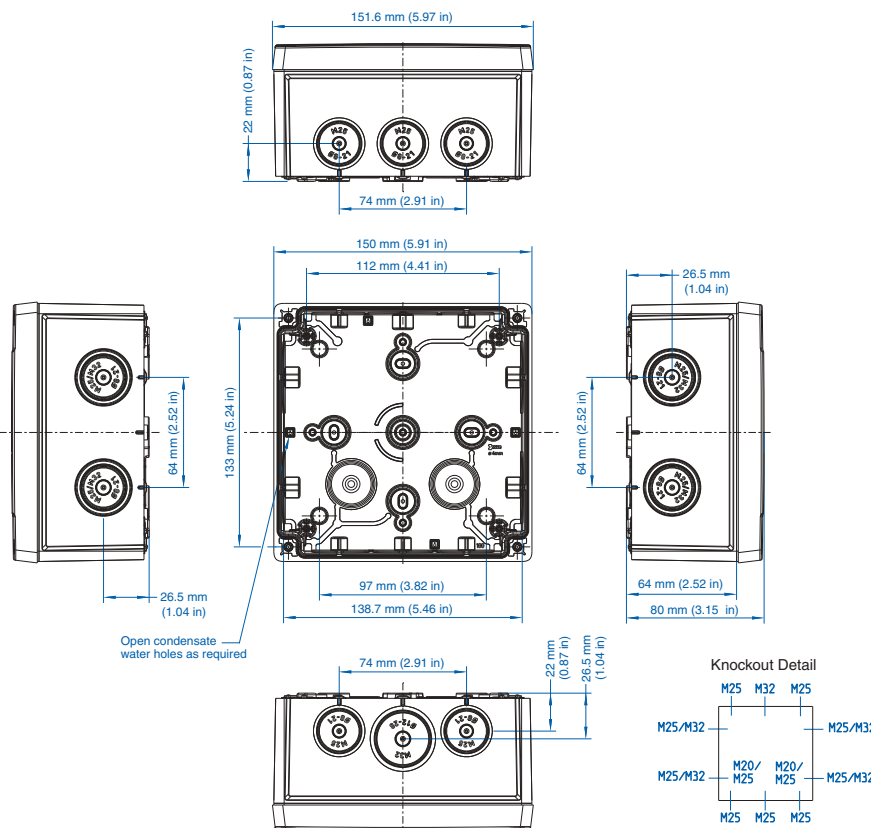

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[810-420-01](#)