

Abox 040 – Polypropylene – 102 x 102 mm (4.02 x 4.02 in.)

Standard Features

- **Protection Level:** IP66
- **Technical:** Self Sealing Soft Elastic Membranes
Suitable for Metric Entry
- **Sealing Area:** M20/M25 - 4 to 21mm
- **UL Recognized Enclosure Material:** Polypropylene
- **Gasket Material:** Thermoplastic Elastomer
- **Color:** Light Gray, White or Black
- **Material Operating Temperature Range:** Polypropylene
-25°C to 55°C (-13°F to 131°F)
- **Accessories:** See section below




Abox

Ordering Information	Cat. No.	Color	Push-In Terminal	Length	Dimensions mm (in)	Height	Std. Pk.
Enclosure with terminals	804-420-01	gray	4 mm ² - 4 pole x 5	102 mm (4.02 in)	102 mm (4.02 in)	57 mm (2.24 in)	3
Enclosure with terminals	804-120-01	white	4 mm ² - 4 pole x 5	102 mm (4.02 in)	102 mm (4.02 in)	57 mm (2.24 in)	3
Enclosure - empty	804-400-01	gray	NA	102 mm (4.02 in)	102 mm (4.02 in)	57 mm (2.24 in)	3
Enclosure - empty	804-100-01	white	NA	102 mm (4.02 in)	102 mm (4.02 in)	57 mm (2.24 in)	3
Enclosure - empty	804-000-01	black	NA	102 mm (4.02 in)	102 mm (4.02 in)	57 mm (2.24 in)	3

Accessories

Ordering Information	Cat. No.	Type	Std. Pk.
DIN Rail TS15 - 15x71 mm	895-204-01	TS15/71	1
Pole Mount Kit (60-170mm)	896-010-01	MABF65-1	1
Terminal (base mount)	896-404-01	2.5/4 mm ² - 5 pole, 41A/690V	10

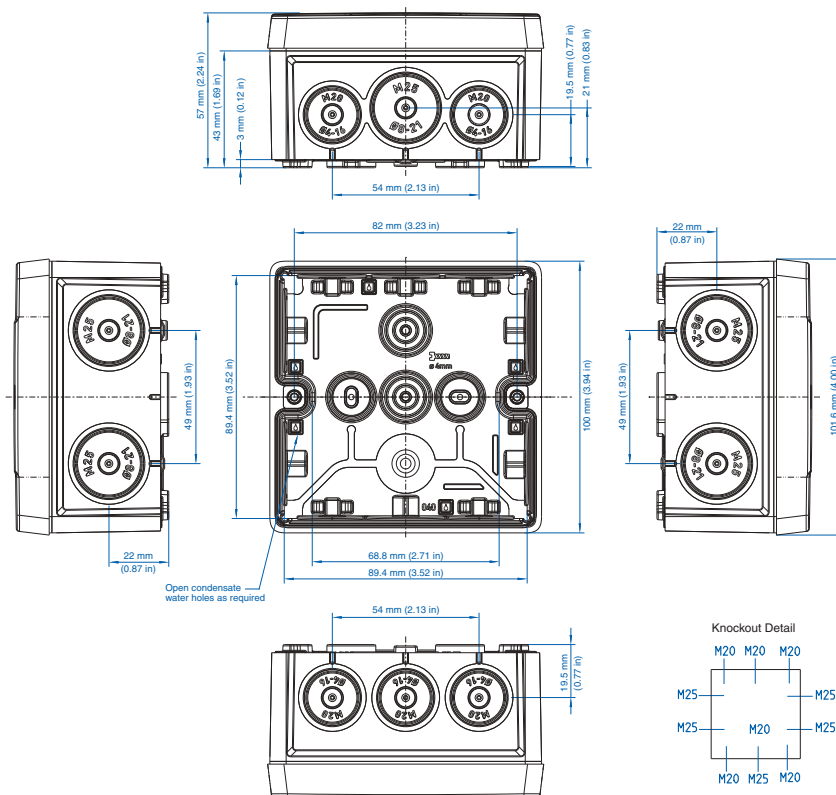

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[804-400-01](#)