 


M8 - Molded Female Cable Assemblies

 
- Female Connector to Flying Lead
- Straight and Angled Connectors
- PVC & PUR Cable
- 3 and 4 pole Connectors
- 1, 2, 5, 10m standard cable length
- Custom cable length available



Straight Connector



Angled Connector



Straight Connectors

Cable Type	Cable Length	Wire Size	3 Pole Cat No.	4 Pole Cat No.
PVC	1m	24AWG	CBF08-S33N0-01BPVC	CBF08-S44N0-01BPVC
	1m	22AWG	CBF08-S33N0-01BP34	CBF08-S44N0-01BP3
	2m	24AWG	CBF08-S33N0-02BPVC	CBF08-S44N0-02BPVC
	2m	22AWG	CBF08-S33N0-02BP34	CBF08-S44N0-02BP34
	5m	24AWG	CBF08-S33N0-05BPVC	CBF08-S44N0-05BPVC
	5m	22AWG	CBF08-S33N0-05BP34	CBF08-S44N0-05BP34
PUR	1m	24AWG	CBF08-S33N0-01BPUR	CBF08-S44N0-01BPUR
	2m	24AWG	CBF08-S33N0-02BPUR	CBF08-S44N0-02BPUR
	5m	24AWG	CBF08-S33N0-05BPUR	CBF08-S44N0-05BPUR

Dimensions (mm) /

(to convert to inches multiply by 0.03937)




Angled Connectors

Cable Type	Cable Length	Wire Size	3 Pole Cat No.	4 Pole Cat No.
PVC	1m	24AWG	CBF08-R33N0-01BPVC	CBF08-R44N0-01BPVC
	1m	22AWG	CBF08-R33N0-01BP34	CBF08-R44N0-01BP34
	2m	24AWG	CBF08-R33N0-02BPVC	CBF08-R44N0-02BPVC
	2m	22AWG	CBF08-R33N0-02BP34	CBF08-R44N0-02BP34
	5m	24AWG	CBF08-R33N0-05BPVC	CBF08-R44N0-05BPVC
	5m	22AWG	CBF08-R33N0-05BP34	CBF08-R44N0-05BP34
PUR	1m	24AWG	CBF08-R33N0-01BPUR	CBF08-R44N0-01BPUR
	2m	24AWG	CBF08-R33N0-02BPUR	CBF08-R44N0-02BPUR
	5m	24AWG	CBF08-R33N0-05BPUR	CBF08-R44N0-05BPUR

Dimensions (mm) /

(to convert to inches multiply by 0.03937)

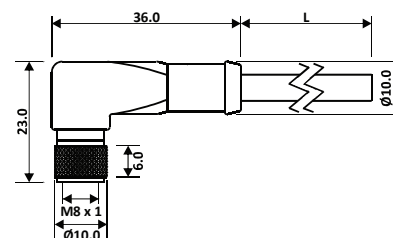

Technical Information

General Specification

Operating Voltage	60V	30V
Current Rating	4A	4A
Insulation Resistance	$\geq 100 \text{ M}\Omega$	$\geq 100 \text{ M}\Omega$
Temperature Range	-25°C...+75°C	-25°C...+75°C
Protection Degree	IP67	IP67

Material Specification

Grip Material	PU	PU
Contact	CU-Zn	CU-Zn
Contact Plating	Gold Plated	Gold Plated
Contact Carrier	Nylon 66	Nylon 66
O-Ring	Neoprene	Neoprene
Grip Color	Black	Black
Coupling Nut	Nickel-Plated Brass	Nickel-Plated Brass

Cable Specifications

Cable Type	PVC/ PUR	PVC/ PUR
Cable Color	Black*	Black*
Wire Size	22AWG (BP34) 24AWG (BPVC, BPUR)	22AWG (BP34) 24AWG (BPVC, BPUR)
Cable Diameter	4.4mm	4.8mm

 
 
 
 
 
*Other colors available, please contact Altech.

M12 Molded Female Cable Assemblies

- Female Connector to Flying Lead
- Straight and Angled Connectors
- PVC & PUR Cable
- 3, 4, 5, 8 and 12 pole Connectors
- 1, 2, 5, 10m standard cable length
- Custom cable length available



Straight Connector



Cable Type	Cable Length	3 Pole Cat No.	4 Pole Cat No.	5 Pole Cat No.	8 Pole Cat No.	12 Pole Cat No.
PVC	1m	CBF12-S43N0-01BPVC	CBF12-S44N0-01BPVC	CBF12-S55N0-01BPVC	CBF12-S88N0-01BPVC	CBF12-S12N0-01BPVC
	1m	CBF12-S43N0-01BP34	CBF12-S44N0-01BP34	CBF12-S55N0-01BP34	-	-
	2m	CBF12-S43N0-02BPVC	CBF12-S44N0-02BPVC	CBF12-S55N0-02BPVC	CBF12-S88N0-02BPVC	CBF12-S12N0-02BPVC
	2m	CBF12-S43N0-02BP34	CBF12-S44N0-02BP34	CBF12-S55N0-02BP34	-	-
	5m	CBF12-S43N0-05BPVC	CBF12-S44N0-05BPVC	CBF12-S55N0-05BPVC	CBF12-S88N0-05BPVC	CBF12-S12N0-05BPVC
	5m	CBF12-S43N0-05BP34	CBF12-S44N0-05BP34	CBF12-S55N0-05BP34	-	-
PUR	1m	CBF12-S43N0-01BPUR	CBF12-S44N0-01BPUR	CBF12-S55N0-01BPUR	CBF12-S88N0-01BPUR	CBF12-S12N0-01BPUR
	2m	CBF12-S43N0-02BPUR	CBF12-S44N0-02BPUR	CBF12-S55N0-02BPUR	CBF12-S88N0-02BPUR	CBF12-S12N0-02BPUR
	5m	CBF12-S43N0-05BPUR	CBF12-S44N0-05BPUR	CBF12-S55N0-05BPUR	CBF12-S88N0-02BPUR	CBF12-S12N0-05BPUR

Angled Connector

PVC	1m	CBF12-R43N0-01BPVC	CBF12-R44N0-01BPVC	CBF12-R55N0-01BPVC	CBF12-R88N0-01BPVC	CBF12-R12N0-01BPVC
	1m	CBF12-R43N0-01BP34	CBF12-R44N0-01BP34	CBF12-R55N0-01BP34	-	-
	2m	CBF12-R43N0-02BPVC	CBF12-R44N0-02BPVC	CBF12-R55N0-02BPVC	CBF12-R88N0-02BPVC	CBF12-R12N0-02BPVC
	2m	CBF12-R43N0-02BP34	CBF12-R44N0-02BP34	CBF12-R55N0-02BP34	-	-
	5m	CBF12-R43N0-05BPVC	CBF12-R44N0-05BPVC	CBF12-R55N0-05BPVC	CBF12-R88N0-05BPVC	CBF12-R12N0-05BPVC
	5m	CBF12-R43N0-05BP34	CBF12-R44N0-05BP34	CBF12-R55N0-05BP34	-	-
PUR	1m	CBF12-R43N0-01BPUR	CBF12-R44N0-01BPUR	CBF12-R55N0-01BPUR	CBF12-R88N0-01BPUR	CBF12-R12N0-01BPUR
	2m	CBF12-R43N0-02BPUR	CBF12-R44N0-02BPUR	CBF12-R55N0-02BPUR	CBF12-R88N0-02BPUR	CBF12-R12N0-02BPUR
	5m	CBF12-R43N0-05BPUR	CBF12-R44N0-05BPUR	CBF12-R55N0-05BPUR	CBF12-R88N0-05BPUR	CBF12-R12N0-05BPUR

Technical Information

General Specification

Operating Voltage	250V	250V	60V	30V	30V
Current Rating	4A	4A	4A	2A	2A
Insulation Resistance	>=100 MΩ	>=100 MΩ	>=100 MΩ	>=100 MΩ	>=100 MΩ
Temperature Range	-25°C...+75°C	-25°C...+75°C	-25°C...+75°C	-25°C...+75°C	-25°C...+75°C
Protection Degree	IP67	IP67	IP67	IP67	IP67

Material Specification

Grip Material	PU	PU	PU	PU	PU
Contact	CU-Zn	CU-Zn	CU-Zn	CU-Zn	CU-Zn
Contact Plating	Gold Plated	Gold Plated	Gold Plated	Gold Plated	Gold Plated
Contact Carrier	Nylon 66	Nylon 66	Nylon 66	Nylon 66	Nylon 66
O-Ring	Neoprene	Neoprene	Neoprene	Neoprene	Neoprene
Grip Color	Black	Black	Black	Black	Black
Coupling Nut	Nickel-Plated Brass	Nickel-Plated Brass	Nickel-Plated Brass	Nickel-Plated Brass	Nickel-Plated Brass

Cable Specification

Cable Type	PVC/ PUR	PVC/ PUR	PVC/ PUR	PVC/ PUR	PVC/ PUR
Cable Color	Black*	Black*	Black*	Black*	Black*
Wire Size	22AWG (BP34, BPUR), 24AWG (BPVC)	22AWG (BP34, BPUR), 24AWG (BPVC)	22AWG (BP34, BPUR), 24AWG (BPVC)	24 AWG	26 AWG
Cable Diameter	4.8mm	4.8mm	5.5mm	6.4mm	6.5mm

*Other colors available, please contact Altech.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[CBF12-R44N0-05BPUR](#) [CBF12-S88S0-10BVC6](#) [CBF12-S12N0-10BPUR](#) [CBF12-S42N0-10BP75](#) [CBF08-R44N0-01BP34](#) [CBF12-S43N0-05BP34](#) [CBF12-R41N0-01BV14-L](#) [CBF08-R33N0-01BP34](#) [CBF12-S42N0-02BP75](#) [CBF12-S54S0-01PCAN](#) [CBF12-R41N0-02BV14-L](#) [CBF12-R44N0-05BP34-B](#) [CBF12-S41N0-1.5GU14-L](#) [CBF12-S43N0-10BP34](#) [CBF12-S43N0-01BP34](#) [CBF12-S44N0-05BTPE](#) [CBF12-R44N0-15BPUR](#) [CBF12-S12N0-10BPVC](#) [CBF12-S88N0-05BPUR](#) [CBF08-S33N0-01BP34](#) [CBF12-S44N0-01BP34](#) [CBF12-S43N2-05BP34-P](#) [CBF08-S44N0-01BP34](#) [CBF12-S40N0-02BV16-L](#) [CBF12-S48S0-10BVC6](#) [CBF12-R43N0-01BP34](#) [CBF12-S41N0-0.5GU14-L](#) [CBF12-R43N0-10BP34](#) [CBF12-R44N0-01BP34](#) [CBF12-R41N0-0.5BV14-L](#) [CBF12-R43N0-02BP34](#) [CBF12-R43N0-05BP34](#) [CBF12-S88N0-10BPUR](#)