

Article Page

Product Description
Name
Order number
Switch type

Signal Type
Illuminant
Connection


Connection diagramm

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Repeat accuracy
Switching state
Digital output
Natural extraneous light
Artificial extraneous light
Material of light outlet
Sensitivity adjustable
Short-circuit proof
Protection category
Housing material
Termination

fork light barrier
KOEG180-Q114AB-DPU-V1-RT
08363333180

 Switchable
DC PNP
 Red light

 Connector

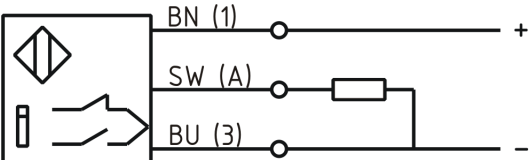

144 x 12 x 204

Throughbeam sensor
10 - 35 V DC
200 mA
< 30 mA
2,5
-10 ° C to 60 ° C
0,01 mm
LED

50000 Lux
50000 Lux
Glas
ja
yes
IP67
Aluminum
Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363333180](#)