

[Article Page](#)

Product Description
 Name
 Order number
 Switch type

fork light barrier
 KOEG50-Q55ZB-DPU-V1-RT
 08363533050



Switchable

DC PNP


● Red light



Connector

Signal Type
 Illuminant
 Connection

Connection diagramm

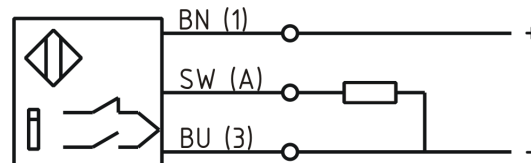

70 x 10 x 89
 90

Dimension (in mm)

art_gewicht

Technical Specification

Signal type

Throughbeam sensor

Operating voltage

10 - 30 V DC

Max. load current

100 mA

Switching frequency

3

Operating temperature

-20 ° C to 60 ° C

Repeat accuracy

0,05 mm

Switching state

LED

Digital output

Natural extraneous light

100000 Lux

Artificial extraneous light

100000 Lux

Material of light outlet

Glas

Sensitivity adjustable

ja

Short-circuit proof

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Housing material

Die-cast zinc

Termination

Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363533050](#)