

[Article Page](#)

Product Description

Name

Order number

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

fork light barrier

KOEG90-Q55AB-DPU-V1-RT

08363333090

 


Switchable


DC PNP



Red light



Connector

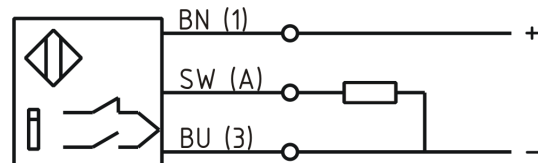

110 x 15 x 90

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Repeat accuracy

Switching state

Digital output

Natural extraneous light

Artificial extraneous light

Material of light outlet

Sensitivity adjustable

Short-circuit proof

Protection category

Housing material

Termination

Throughbeam sensor

10 - 35 V DC

200 mA

< 30 mA

2,5

-10 ° C to 60 ° C

0,01 mm

LED

50000 Lux

50000 Lux

Glas

ja

yes

IP67

Aluminum

Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363333090](#)