 



[Article Page](#)

Product Description
Name
Order number
Matchcode
Illuminant
Connection

one-way light barrier
KOES12M-Q30KB-D-IR
08363820700
9882-0700
IR Infrared light 880 nm

Connection diagramm

 Cable

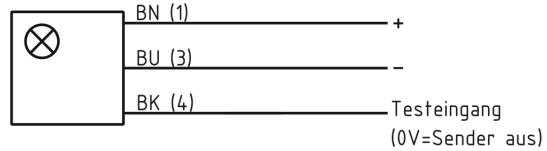

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Operating temperature
Digital output
Measuring range
Sensitivity adjustable
Sensing range adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

15 x 30 x 30
Throughbeam sensor
10 - 36 V DC
200 mA
< 15 mA
-25 ° C to 55 ° C
12 m
ja
nein
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Plastic
3m PVC 4x0,14mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363820700](#)