


[Article Page](#)

Product Description
 Name
 Order number
 Matchcode
 Illuminant
 Connection

one-way light barrier
 KOES12M-Q30KB-D-V1-IR
 08363820764
 9882-0764
 IR Infrared light 880 nm

Connection diagramm

 Connector

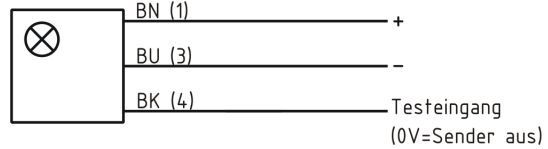

Dimension (in mm)
 Technical Specification
 Signal type
 Operating voltage
 Max. load current
 No load current
 Operating temperature
 Digital output
 Measuring range
 Sensitivity adjustable
 Sensing range adjustable
 Short-circuit proof
 Overload protection
 Reverse voltage protection
 Protection category
 EMC-level
 Housing material
 Termination

15 x 30 x 30
 Throughbeam sensor
 10 - 36 V DC
 200 mA
 < 15 mA
 -25 ° C to 55 ° C
 12 m
 ja
 nein
 yes
 yes
 yes
 IP67
 DIN EN 60947-5-2:2008
 Plastic
 Connector M8 3pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363820764](#)