
 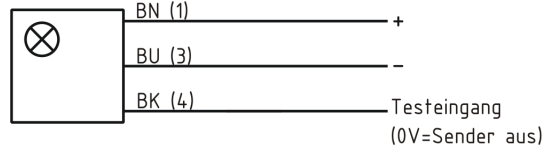


[Article Page](#)

Product Description
Name
Order number
Matchcode
Illuminant
Connection

one-way light barrier
KOES22M-Q64KB-D-IR
08363215000
RP64-T022MD-EY6C3L2
IR Infrared light 880 nm

Connection diagramm



Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Operating temperature
Operating state
Measuring range
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination
Notes

Q 20 x 60 x 43
Throughbeam sensor
10 - 30 V DC
100 mA
< 35 mA
-25 ° C to 55 ° C
LED
22 m
yes
IP67
DIN EN 60947-5-2:2008
Plastic
2m PVC 3x0,5mm²
Sender mit Testeingang

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363215000](#)