

[Article Page](#)

Product Description

Name

one-way light barrier

Order number

KOES60M-M30MB96-DPA-V2-IR

Switch type

08363255038



Changeover

Signal Type

DC PNP

Illuminant


IR Infrared light 880 nm

Connection



Connector

Connection diagramm

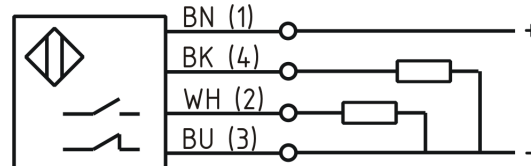

Technical Specification

Signal type

Throughbeam sensor

Operating voltage

10 - 30 V DC

Max. load current

150 mA

No load current

< 30 mA

Switching frequency

150

Operating temperature

-25 ° C to 70 ° C

Operating state

LED

Switching state

LED

Digital output

Measuring range

60 m

Sensitivity adjustable

ja

Sensing range adjustable

nein

Short-circuit proof

yes

Overload protection

yes

Reverse voltage protection

yes

Protection category

IP67

EMC-level

DIN EN 60947-5-2:2008

Termination

Connector M12 4pol

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08363255038](#)