

[Article Page](#)

Product Description

Name

Order number

Matchcode

Switching distance

Switch type

Signal Type

Illuminant

Connection

Connection diagramm

reflex light probe

KORT200-Q20KB-DPA-RT

08361205002

UP-D0200P-CX6C4U2

200 mm




Changeover

DC PNP

● Red light 680 nm



Cable

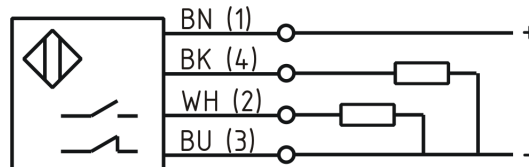

8 x 20 x 35

Dimension (in mm)

Technical Specification

Signal type

Operating voltage

Max. load current

No load current

Switching frequency

Operating temperature

Operating state

Switching state

Digital output

Sensitivity adjustable

Sensing range adjustable

Short-circuit proof

Overload protection

Reverse voltage protection

Protection category

EMC-level

Housing material

Termination

Diffuse mode sensor

10 - 30 V DC

150 mA

< 25 mA

300

-20 ° C to 55 ° C

LED

LED

ja

nein

yes

yes

yes

yes

IP67

DIN EN 60947-5-2:2008

Plastic

2m PVC 4x0,15mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361205002](#)