
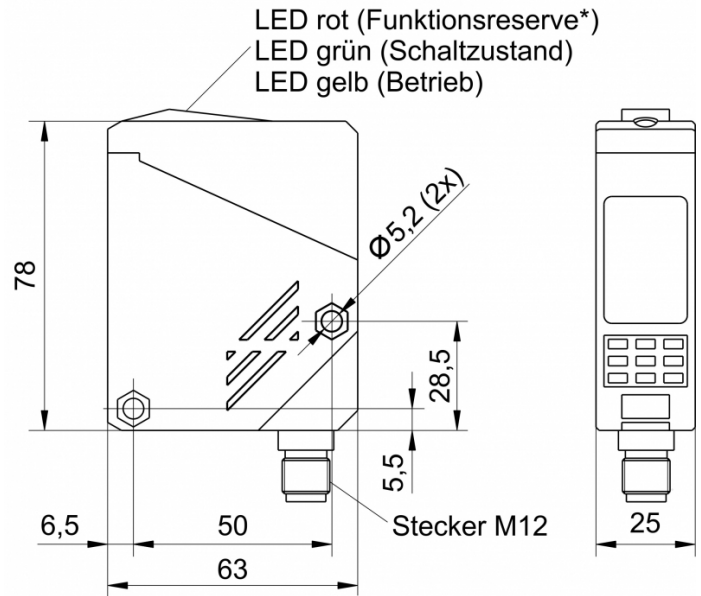


[Article Page](#)

Product Description


reflex light probe

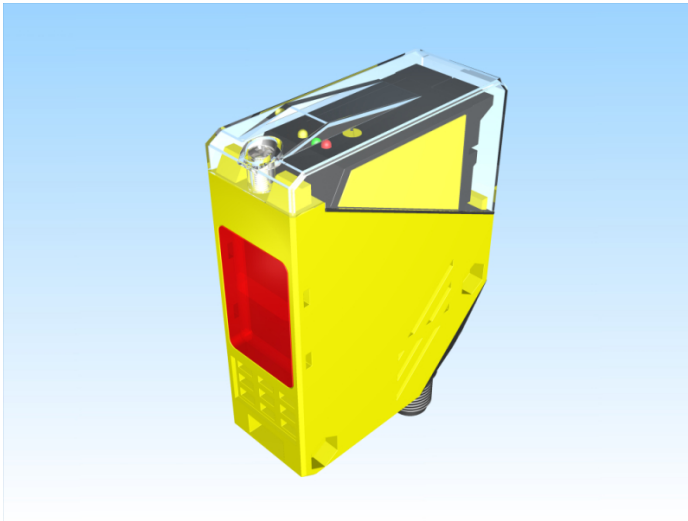

Name
Order number
Switching distance
Switch type

Signal Type
Illuminant
Connection
Connection diagramm

KORT800-Q76KB-DPU-V2-IR
08361280026
from 800 mm to 800 mm
 Switchable
PNP
 Infrared light 880 nm
connector M12

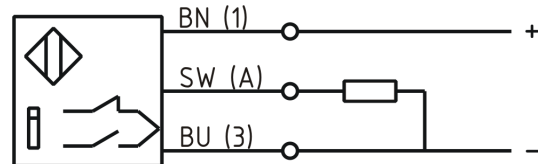

Q 25 x 77.5 x 63

Dimension (in mm)
Technical Specification
Signal type
Operating voltage
Max. load current
No load current
Switching frequency
Operating temperature
Operating state
Switching state
Sensitivity adjustable
Short-circuit proof
Overload protection
Reverse voltage protection
Protection category
EMC-level
Housing material
Termination

Diffuse mode sensor
10 - 30 V DC
100 mA
< 35 mA
250 Hz
-25 ° C to 55 ° C
LED
LED
ja
yes
yes
yes
IP67
DIN EN 60947-5-2:2008
Plastic
Connector M12 4 pol (pivotal: 0° oder 90°)

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08361280026](#)