 



[Article Page](#)

Product Description
 Name
 Order number
 Switching distance
 Mounting


inductive sensor DC
 SC1,5-M8MB45-DPS
 08323080151
 1,5 mm



 
Switch type



Signal Type
 Connection

 

Connection diagramm

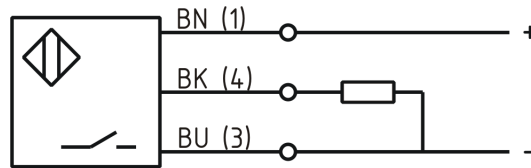

Dimension (in mm)
 Technical Specification

fine-pitch thread M8 x 45

Operating voltage
 Max. ripple
 Voltage drop
 Max. load current
 No load current
 Leakage current
 Switching frequency
 Switching hysteresis
 Operating temperature
 Temperature drift
 Repeat accuracy
 Switching state
 Digital output
 Short-circuit proof
 Overload protection
 Reverse voltage protection
 Protection category
 EMC-level
 Material active face
 Termination

10 - 30 VDC
 $\leq 10 \%$
 2 V
 200 mA
 $\leq 10 \text{ mA}$
 $\leq 10 \mu\text{A}$
 100
 $\leq 15 \%$
 -25 ° C to 70 ° C
 $\leq 10 \%$
 $\leq 5 \%$
 LED
 yes
 yes
 yes
 IP67
 DIN EN 60947-5-2:2008
 POM
 2m PUR 3x0,15 mm²

Errors and omissions exceptet

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[08323080151](#)