

# Fuse Blocks, 5 x 20 and 5 x 25 mm

DDFL4U(LR): This is a modified version of DDFL4U(E) terminal where in two equipotential connection points are available on both ends of the terminal.


CAFL4U(L) is equipped with a LED for blown fuse indication. CAFL4U(N) is equipped with a neon bulb for same application.

**Important:**


The disconnecting device is not suitable for interrupting load. The supply must be switched off before operating the slide link/lever.

† Fuses are sold separately Altech, see pages 23-24.

\* Add required voltage to part number as suffix, i.e. DDFL4U(E)/24 for 24V AC/DC

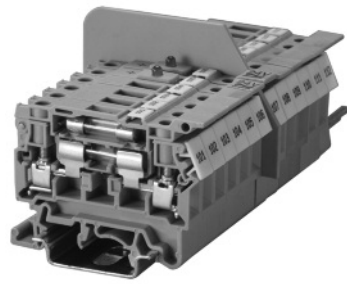

**DDFL4U(E)LR\***

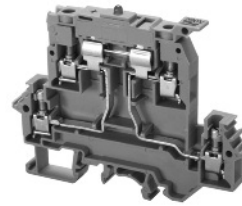

† Fuse not included.

Terminal Width	8 mm
Height x Length	66 x 88 mm
Stripping Length	9.5 mm
Insulation Material	Polyamide 6.6
Type of Connection	4 screw clamps
LED Voltage	24V AC/DC, 48V AC/DC, 110V AC/DC, 220V AC

**Type of Fuse Used** **Ø5x20, Ø5x25 mm**

Approvals			
Wire Range	22-10 AWG	0.5-4 sq.mm	22-10 AWG
Voltage Rating	600 V	500 V	600 V
Current Rating	6.3 A	6.3 A	6.3 A
Torque	7 lb-in	0.5 Nm	7 lb-in

Other Approvals

**Cat. No.** **Std. Pk.**

<b>DDFL4U(E)LR*</b>	20
EPDDFL4U	20



CA702	50
CA802	50
CA202	50

CA730/2	100
CA730/3	50
CA730/4	50
CA730/10	10

CA740/2	100
CA740/3	50
CA740/4	50
CA740/10	10

CA703/7	100
CA704/7	100
CA705/7	100
CA738/10	100

CA707/S/Q/8	100
-------------	-----

CA711/2	100
CA711/3	100
CA711/4	50
CA711/10	25

Marking Tags (MT Type)	100
(MT Type on Lever)	100

**Terminal Block**

End Plate	
-----------	--

DIN Rail for ordering information refer to page 72

End Stop for ordering information refer to page 74	
--	--

Internal Jumper	2 pole	
	3 pole	
	4 pole	
	10 pole	

Insulated Internal Jumper	2 pole	
	3 pole	
	4 pole	
	10 pole	

Current Bar	2 pole	
	3 pole	
	4 pole	
	10 pole	

Shorting Sleeve & Screw	
-------------------------	--

External Jumper	2 pole	
	3 pole	
	4 pole	
	10 pole	

**COLOR BLOCKS**  
(other than grey standard)

When ordering please add color suffix to Cat. No.

Example: CTS2.5U-N/R

<b>Color</b>	<b>Ordering Suffix</b>	
Red	R	
Blue	BU	
Black	BL	
Orange	O	
Green	G	
Yellow	Y	
White	W	
Beige	BG	
Dark Brown	DB	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Altech:](#)

[DDFL4U\(E\)LR48](#)