

### Features:

- USA Fixed AC Head
- 1 Year Warranty
- Level VI Efficiency
- Universal Input
- UL Approved
- Small and Compact Design



SPECIFICATION			
Part Number	T6639ST	T6640ST	T6642ST
AC Input Voltage	90-264VAC		
AC Input Frequency	47-63Hz		
AC Input Current	0.5A Max		
AC Inrush Current	No Damage		
Output Voltage	+12V	+12V	+5V
Min Load Current	0A		
Nominal Load Current	1A	2A	2.5A
Nominal Output Power	12W	24W	12.5W
Output Regulation	+-5%		
Line Regulation	+-2%		
Ripple & Noise	300mV p-p		
Average Efficiency	82%		
Rise Time	100mS		
Turn On Delay	3s		
Size	70 x 30 x 29 mm		
Weight	120g		
Input Plug Type	USA Fixed		
Output Cord	18AWG 1500 Jackplug 5.5 x 2.1 x 12mm		
Operating Temperature	0 - 40 Deg C		
Storage Temperature	-20 to 60 Deg C		
Operating Humidity	20 - 85%		
Storage Humidity	5 - 95%		
Hi Pot	3000VAC 10mA 1 Min		
Leakage Current	0.25mA Max		
Safety	UL		
EMI	EN55022		
MTBF	50K Hours		

## Stontronics Ltd


Chancerygate Business Centre, Cradock Road, Reading, Berkshire, RG2 0AH.

Tel: +44 (0) 118 931 1199 • Fax: +44 (0) 118 931 1145 • Email: [info@stontronics.co.uk](mailto:info@stontronics.co.uk) • Web: [www.stontronics.com](http://www.stontronics.com)

Please Note: Image shown is representative of entire range. Individual PSU image &/or drawings or data sheets available on request.

Stontronics Ltd accepts no responsibility for typographical errors in the production of this leaflet. Product specifications are subject to change without notice.



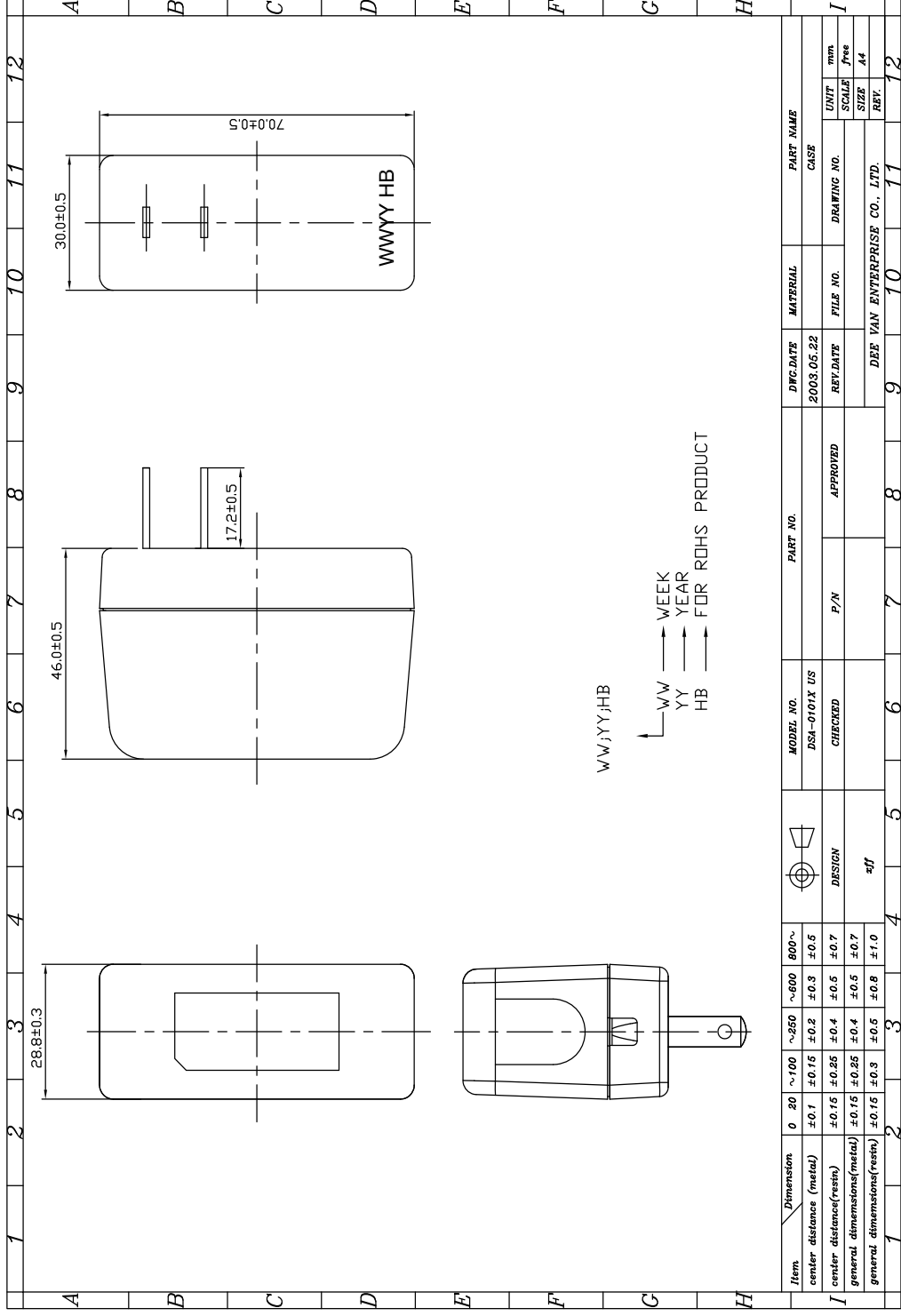

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cicor:](#)

[T6640ST](#) [T6642ST](#)