



Pushing Performance
Since 1945

Han 40EEE PCB adapter

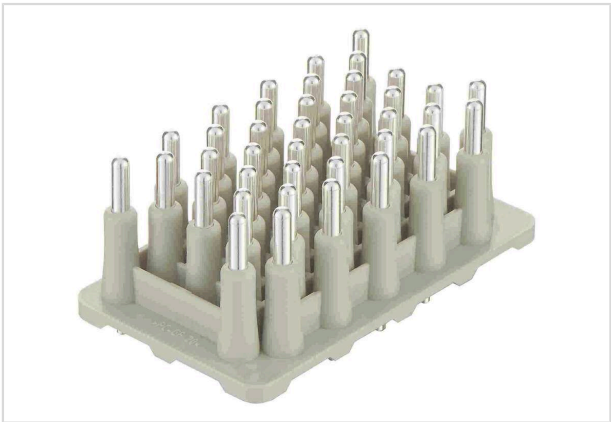


Image is for illustration purposes only. Please refer to product description.

Part number	09 33 000 9880
Specification	Han 40EEE PCB adapter
HARTING eCatalogue	https://b2b.harting.com/09330009880

Identification

Category	Accessories
Type of accessory	PCB adapter
Description of the accessory	In the Han [®] 40 EEE crimp insert

Version

Gender	Male Female
Size	16 B
Number of contacts	40

Technical characteristics

Rated current	16 A
Rated voltage	500 V
Rated impulse voltage	6 kV
Pollution degree	3
Limiting temperature	-40 ... +125 °C

Material properties

Material (insert)	Polycarbonate (PC)
Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight



Pushing Performance
Since 1945

Material properties

ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

Commercial data

Packaging size	10
Net weight	15 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140190696
ETIM	EC002637
eCl@ss	27460201 PCB connector (board connector)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09330009880](#) [9330009880](#)