

VarioShell-HC650 insulation cover

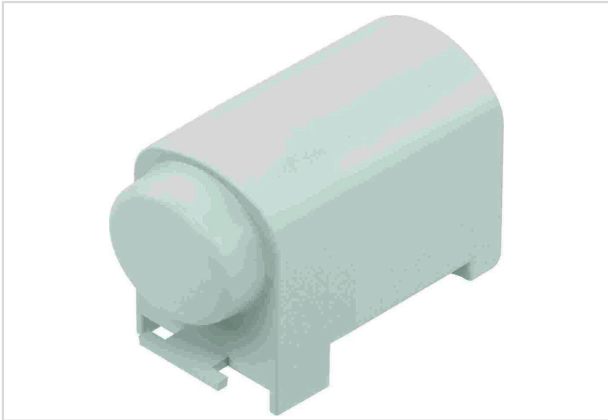


Image is for illustration purposes only. Please refer to product description.

Part number	09 40 124 9912
Specification	VarioShell-HC650 insulation cover
HARTING eCatalogue	https://b2b.harting.com/09401249912

Identification

Category	Accessories
Series	Han® HC Modular
Identification	650
Series of hoods/housings	Han® HPR VarioShell
Type of accessory	Protection cover
Description of the accessory	for cable shoes

Technical characteristics

Rated voltage	4,000 V
Rated impulse voltage	18 kV
Pollution degree	3
Overvoltage category	II
Insulation resistance	$>10^{10} \Omega$
Limiting temperature	-40 ... +125 °C

Material properties

Material (accessories)	Polycarbonate (PC)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Not contained
-----------------------	---------------

Commercial data

Packaging size	1
Net weight	51 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140279490
ETIM	EC002314
eCl@ss	27440208 Cap for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09401249912](#) [9401249912](#)