

har-key latching 90°



Image is for illustration purposes only. Please refer to product description.

Part number	09 45 453 2304
Specification	har-key latching 90°
HARTING eCatalogue	https://b2b.harting.com/09454532304

Identification

Category	Operator interfaces
Series	har-key
Element	Key switches
Specification	latching 90°

Version

Diameter of the mounting hole	30.5 mm
Details	This item requires additional contact blocks and a module holder to be functional. Please select these under "Matching Products".

Technical characteristics

Actuation path	6 mm
Overvoltage category	III (protection by low voltage)
Tightening torque	≤2.5 Nm Fixing nut
Operating temperature	-40 ... +70 °C
Storage temperature	-50 ... +85 °C
Degree of protection acc. to IEC 60529	IP65
Isolation group	I (600 ≤ CTI)
Thickness of the panel	1 ... 8 mm

Material properties

Colour	anthracite
--------	------------


Specifications and approvals

Specifications	EN 60947-5-1
	UL 60947-5-1 NKCR.E534795
UL / CSA	CSA C22.2 No. 60947-5-1:22 NKCR7.E534795
	UL 60947-1 NKCR.E534795
	CSA C22.2 No. 60947-1:22 NKCR7.E534795

Commercial data

Packaging size	10
Net weight	1 g
Country of origin	Germany
European customs tariff number	85365080
GTIN	5713140449756
ETIM	EC000222

Switching position

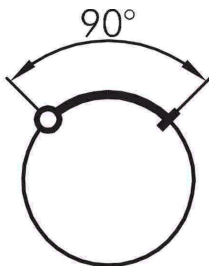

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09454532304](#)