

Patch Cable 10m CAT6 pvc

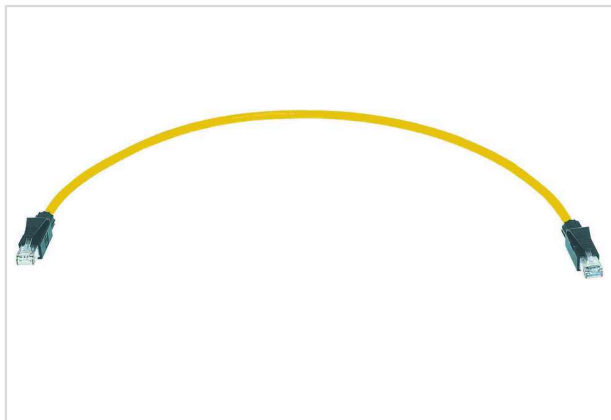


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 751 1551
Specification	Patch Cable 10m CAT6 pvc
HARTING eCatalogue	https://b2b.harting.com/09457511551

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING RJ Industrial®
Connector 2	HARTING RJ Industrial®
Type of cable	Copper cable (round)

Version

Cable length	10 m
Number of cores	8
Core structure	4x 2x AWG 26/7

Technical characteristics

Transmission characteristics	Cat. 6 _A Class E _A up to 500 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s

Material properties

Material (cable)	PVC
------------------	-----



Pushing Performance
Since 1945

Material properties

Colour (cable)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Commercial data

Packaging size	1
Net weight	553 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140063792
eCl@ss	27060308 Patch cord copper (data cable)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09457511551](#)