

## ix Type A AWG28 CAT6A PVC 0.6m

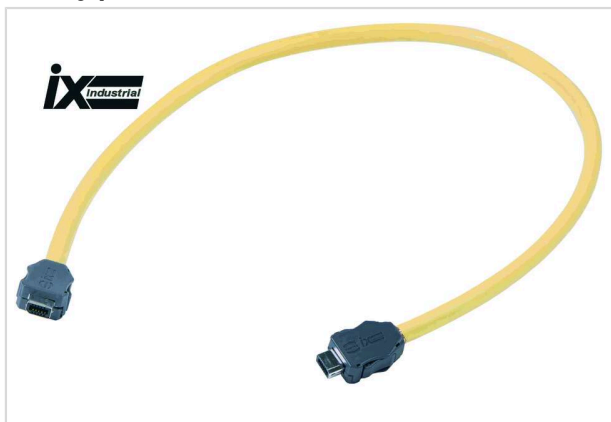


Image is for illustration purposes only. Please refer to product description.

Part number	33 48 060 6830 006
Specification	ix Type A AWG28 CAT6A PVC 0.6m
HARTING eCatalogue	<a href="https://b2b.harting.com/33480606830006">https://b2b.harting.com/33480606830006</a>

### Identification

Category	System cabling
Series	HARTING ix Industrial®
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING ix Industrial® Type A
Connector 2	HARTING ix Industrial® Type A
Type of cable	Copper cable (round)

### Version

Cable length	0.6 m
Number of cores	8
Core structure	4x 2x AWG 28/7
Termination method	Solder termination
Coding	Type A

### Technical characteristics

Transmission characteristics	Cat. 6 <sub>A</sub> Class E <sub>A</sub> up to 500 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s



Pushing Performance  
Since 1945

## Technical characteristics

Limiting temperature	-40 ... +80 °C
----------------------	----------------

## Material properties

Material (cable)	PVC
Colour (cable)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

## Specifications and approvals

Specifications	IEC 61076-3-124
----------------	-----------------

## Commercial data

Packaging size	1
Country of origin	Vietnam
European customs tariff number	85444290
GTIN	5713140259775
ETIM	EC002599
eCl@ss	27060390 Ready-made data cable (unspecified)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[33480606830006](#)