

## ix Type A - RJ45 AWG28 CAT6A PVC 0.4m

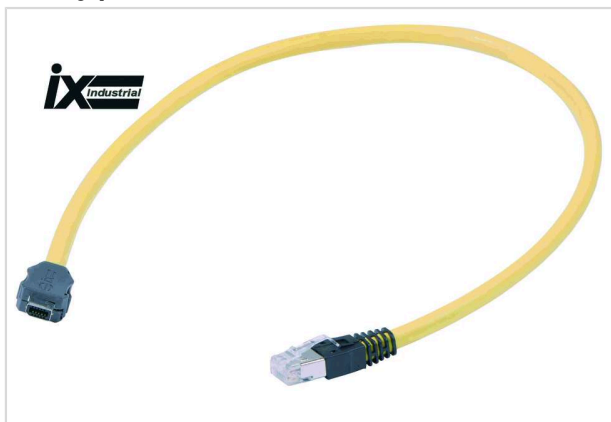


Image is for illustration purposes only. Please refer to product description.

Part number	33 48 065 3830 004
Specification	ix Type A - RJ45 AWG28 CAT6A PVC 0.4m
HARTING eCatalogue	<a href="https://b2b.harting.com/33480653830004">https://b2b.harting.com/33480653830004</a>

### Identification

Category	System cabling
Series	HARTING ix Industrial® RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING ix Industrial® Type A Solder termination
Connector 2	RJ45 Piercing termination
Type of cable	Copper cable (round)

### Version

Cable length	0.4 m
Number of cores	8
Core structure	4x 2x AWG 28/7

### Technical characteristics

Transmission characteristics	Cat. 6 <sub>A</sub> Class E <sub>A</sub> up to 500 MHz
Data rate	10 Mbit/s 100 Mbit/s 1 Gbit/s 2.5 Gbit/s 5 Gbit/s 10 Gbit/s



**Pushing Performance**  
Since 1945

## Technical characteristics

Limiting temperature	-40 ... +70 °C
----------------------	----------------

## Material properties

Material (cable)	PVC
Colour (cable)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

## Specifications and approvals

Specifications	IEC 61076-3-124
----------------	-----------------

## Commercial data

Packaging size	1
Country of origin	Vietnam
European customs tariff number	85444290
GTIN	5713140264069
ETIM	EC002599
eCl@ss	27060390 Ready-made data cable (unspecified)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[33480653830004](#)