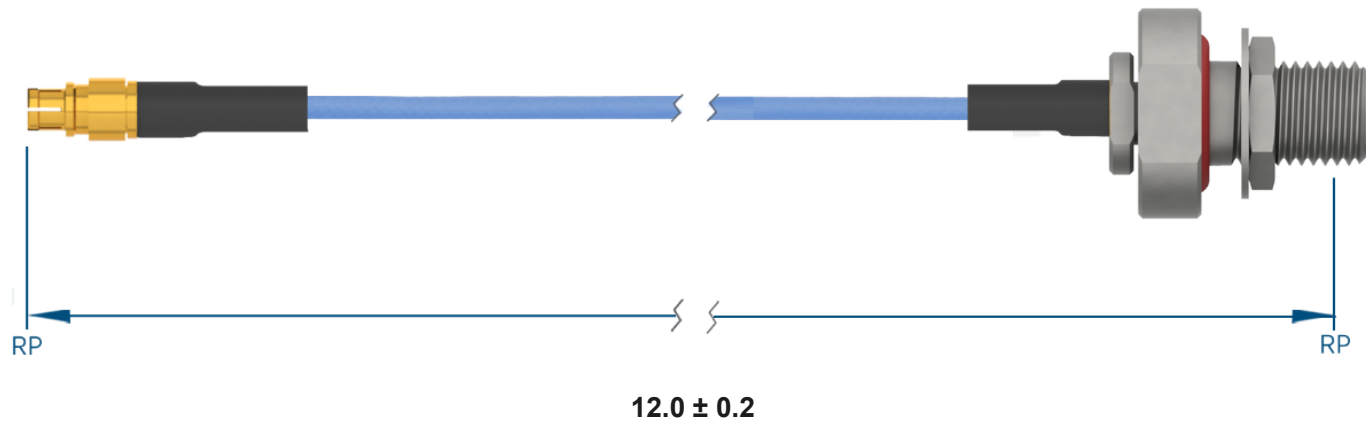


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMPM Straight Female (3221-40007)
 2.92mm Bulkhead Female (SF1521-60045)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
 1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 3.27 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMPM Straight Female to 2.92mm Bulkhead Female
 12" Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FSSMPM-047-FB292-120

DRAWN

2022-10-26 12:14:52

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-047-FB292-120](#)