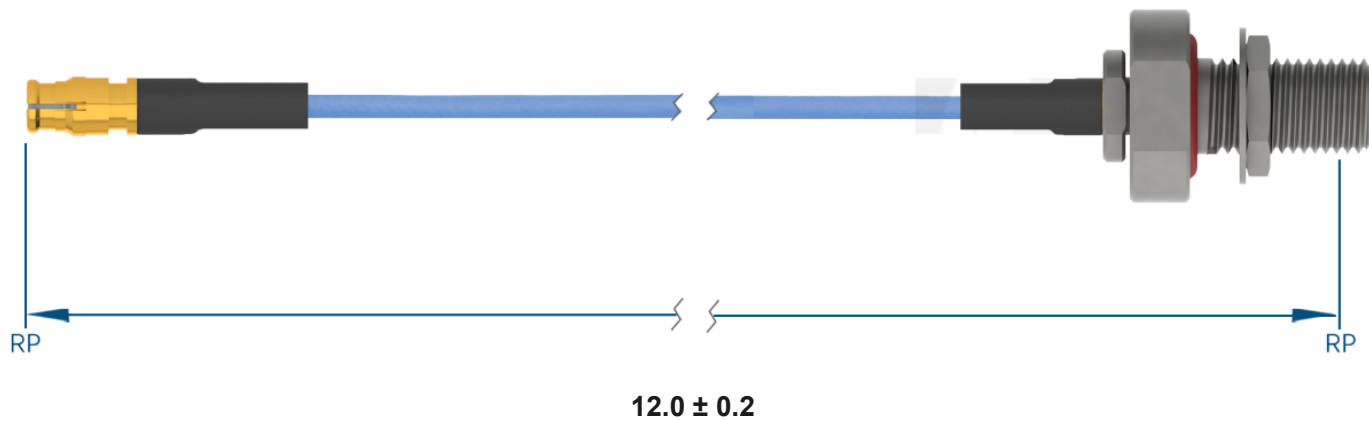


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMP Straight Female (1221-4010)
 SMA Bulkhead Female (2944-6001)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
 1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 2.26 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMP Straight Female to SMA Bulkhead Female 12"
 Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FSSMP-047-FBSMA-120

DRAWN

2022-10-19 16:10:16

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMP-047-FBSMA-120](#)