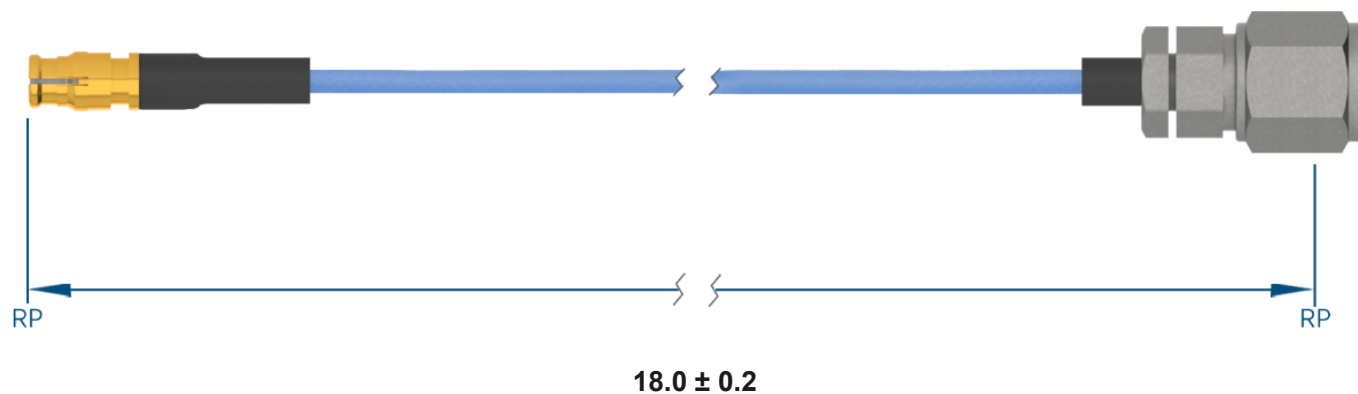


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMP Straight Female (1221-4010)
2.4mm Straight Male (SF1611-60001)
CABLE: Ø.047 Flexible Coax
SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms
FREQ. RANGE: DC to 40 GHz
VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz
INSERTION LOSS: 4.65 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMP Straight Female to 2.4mm Straight Male 18"
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FSSMP-047-MS24-180

DRAWN

2022-10-26 11:32:43

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMP-047-MS24-180](#)